



PACO 19

FLUSH MOUNT CEILING

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

The low-profile Paco 19 flush mount uses a multi-layered glass, with two cylindrical sections fused together onto a flat white glass. The top portion is opal glossy glass with a contemporary polished finish, and the bottom is a clear blown glass with an outer texture of coarse sandstone resembling the beautiful cut patterning of a rock formation. The tranquil glow has a low key harmonious display that exudes a warm mood. When lit the glass is vitalizing as well as stylish.

LAMPING

Incandescent: 4x 40W T10 Medium base, 120V, lamp not included.

LED: 4x 9W Replaceable T-shape LED source, 120V, 90+ CRI, 3000°K CCT, 800 lumens, 30,000 hours, included.

DIFFUSER

Handcrafted glass diffuser in Opal Glossy with clear or smoke stone trim. 19" Dia. x 6" H

CONSTRUCTION

Stamped aluminum fitter is powder coated white.

MOUNTING


Installs directly to a 4" octagonal outlet box, centered on fixture. 90°C supply wire required for incandescent lamping.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



OPAL/SMOKE STONE (PACO19CLC)

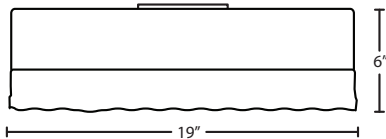

PACO19CLC
OPAL/CLEAR STONE

ORDERING:

SHADE OPTIONS	-	LAMP OPTIONS
PACO19CLC Opal/Clear		(blank) 4x 40W T10 Incan
PACO19SMC Opal/Smoke		LED 4x 9W T12 LED, 3000K

Ex. PACO19SMC

Paco 19 Ceiling w/ Opal/Smoke Glass,
Satin Nickel Finish



Project Information:

All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 3/22