



PAOLO

MINI SCONCES WALL

ADA

COMPLIANT

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

Wall-mounted **ADA-compliant** sconce featuring one handcrafted glass.

LAMPING

Standard: 50W G9 Halogen 120V, suitable for dimming, lamp included.

LED: 5W Replaceable source, 120V, CL dimmable, 90+ CRI, 3000°K CCT, 450 lumens, 25,000 hours, lamp included.

DIFFUSER

Diffuser shall be handcrafted glass of various decors.

CONSTRUCTION

Rectangular canopy (4.75" x 5.5" H) and lampholder are stamped steel, with plated finish.

METAL FINISH


Fixture shall be finished in Bronze, Chrome, or Satin Nickel.

MOUNTING

Installs directly to a 4" octagonal outlet box. Orient horizontal or vertical, wall-mount only.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).

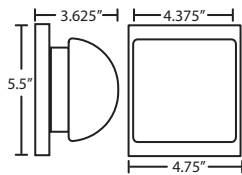

PAOLO SHOWN IN GLITTER (7873GL) IN CHROME FINISH

787307
OPAL MATTE

787319
CARRERA

787399
OPAL-FROST

78735T
STUCCO



ORDERING:

FIXTURE	DECOR	LAMPING OPTIONS	METAL FINISH
1WS Sconce	787307 Opal Matte	(blank) 50W G9 Hal	BR Bronze
	787319 Carrera	LED 5W LED 120V,	CR Chrome
	787399 Opal-Frost	dimmmable	SN Satin Nickel
	7873GL Glitter		
	78735T Stucco		

Ex. 1WS-787319-SN

Paolo Mini Sconce w/ Carrera Glass,
Satin Nickel Finish

Project Information:

All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 12/18