



PICA 11 / 14 / 17

FLUSH MOUNT CEILING

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

Flush-mounted ceiling fixture, featuring handcrafted glass.

LAMPING

Standard: 60W A19 Medium-based 120V incandescent, lamp not included.

Dimmable with standard incandescent dimmer (not included).

LED: 9W Replaceable source, 120V, dimmable, 90+ CRI, 3000°K CCT, 800 lumens, 30,000 hours, lamp included.

DIFFUSER

Handcrafted glass diffuser is available in various decors.

Pica 11: 11" Dia. x 4.2" H

Pica 13: 13.4" Dia. x 4.4" H

Pica 17: 16.6" Dia. x 4.8" H

CONSTRUCTION

Glass diffuser is secured to fitter with "twist & lock" bayonet action. Stamped aluminum fitter is powder coat White finish.

MOUNTING

Installs directly to a 4" octagonal outlet box, centered on fixture.

90°C supply wire required for incandescent lamping.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



PICA SHOWN IN GOLD SAND



Twist and lock bayonet glass

CREME SAND

WHITE SAND



For ordering information, see next page


All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 12/18




ORDERING:

Pica 11: #9664

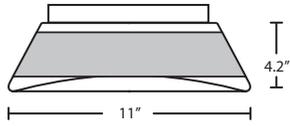


FIXTURE/DECOR	LAMP OPTIONS
9664CRC 11.0" Dia. Creme Sand	(blank) 1x 60W A19 Incan
9664GDC 11.0" Dia. Gold Sand	LED 1x 9W LED
9664WHC 11.0" Dia. White Sand	

Pica 14: #9663

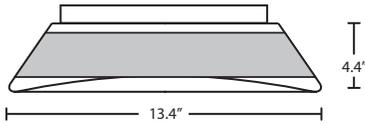

FIXTURE/DECOR	LAMP OPTIONS
9663CRC 13.4" Dia. Creme Sand	(blank) 2x 60W A19 Incan
9663GDC 13.4" Dia. Gold Sand	LED 2x 9W LED
9663WHC 13.4" Dia. White Sand	

Pica 17: #9662

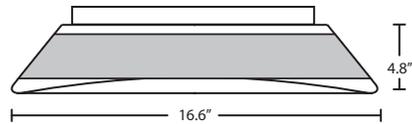

FIXTURE/DECOR	LAMP OPTIONS
9662CRC 16.6" Dia. Creme Sand	(blank) 3x 60W A19 Incan
9662GDC 16.6" Dia. Gold Sand	LED 3x 9W LED
9662WHC 16.6" Dia. White Sand	

Ex. 9662GDC
Pica 17 Ceiling, Gold Sand Glass

Project Information: