



PRISMO 10 / 16

SCONCES OUTDOOR

location:  
**WET**

**SPECIFICATIONS:**

**DESCRIPTION**

Wall-mounted sconce featuring handcrafted frosted glass.

**LAMPING**

**Standard:** 60W A19 120V incandescent, lamp not included.  
Dimmable with standard incandescent dimmer (not included).  
**LED:** 8W Replaceable LED source, 120V, CL dimmable, 90+ CRI, 3000°K CCT, 800 lumens, 30,000 hours, lamp included.

**DIFFUSER**

Wall-mounted sconce featuring handcrafted frosted glass.

**CONSTRUCTION**

Stamped aluminum fitter is powder coated white.  
Glass is secured by stainless steel set screws.  
Prismo 10 fitter is 4.125" W x 7.375" H x 0.75" D  
Prismo 16 fitter is 4.125" W x 12" H x 0.8" D

**MOUNTING**

Installs directly to a 4" octagonal outlet box. 75°C supply wire required for incandescent lamping. Fixture is centered on the outlet box. 10' fixture centerline is 0.75" below box centerline. Orient horizontal or vertical, wall-mount only.


**LABELS**

UL or ETL Listed. Suitable for Wet Locations (interior or exterior use).




PRISMO 16 & PRISMO 10 SHOWN IN FROST/CLEAR

**Prismo 10: #3045**

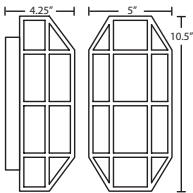

FIXTURE	LAMP OPTIONS
<b>304504</b> 10.5" H Frost/Clear	<b>(blank)</b> 1x 60W A19 Incan <b>LED</b> 1x 8W LED 120V, dimmable

**Prismo 16: #3046**

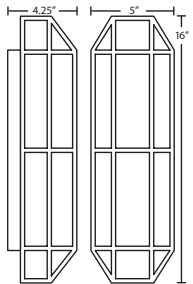

FIXTURE	LAMP OPTIONS
<b>304604</b> 16" H Frost/Clear	<b>(blank)</b> 2x 60W A19 Incan <b>LED</b> 2x 8W LED 120V, dimmable

**Ex. 304604**  
2 Lt. Prismo 16 Sconce w/ Frost/Clear Glass,  
White Finish

**Project Information:**

Empty box for project information.

All dimensions provided are nominal.  
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 12/18