



# RENFRO 16

FLUSH MOUNT CEILING

location:  
**DAMP**

## SPECIFICATIONS:

### DESCRIPTION

Ultra low profile ceiling luminaire, featuring handcrafted glass.

### LAMPING

**FL:** T5 Circline, 120V, not included.

**Halogen:** 40W low-pressure G9 Halogen 120V lamps, included.

**LED:** 16W Integrated source, 120V, CL dimmable, 85+ CRI, 3000°K CCT, 1500 lumens, 30,000 hours, included.

### DIFFUSER

Handcrafted glass diffuser is available in various decors. 15.75" Dia. x 3" H

### CONSTRUCTION

Fabricated aluminum fitter is powder coated White.

### MOUNTING

Installs directly to a 4" octagonal outlet box, centered on fixture.


90°C supply wire required for incandescent lamping.

### LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



RENFRO CEILING SHOWN IN WHITE SPARKLE

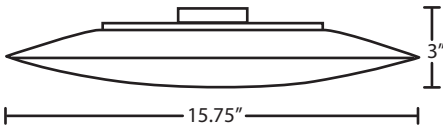

FIXTURE/DECOR	LAMP OPTIONS
RENFRO16WS 15.75" Dia. White Sparkle	<b>HAL</b> 2x 40W G9 Hal <b>LED</b> 16W LED, 1500 lumens

**Project Information:**

All dimensions provided are nominal. Allowance must be made for dimensional tolerance in handcrafted glasses.