



ROCKY

120V PENDANTS

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

The Rocky Pendant features a unique European globe shade that melds the beauty of shimmering glass with the visual advantages of cut metal, which results in a compelling optical display in a smartly modern design.

LAMPING

Standard: 60W Medium-based 120V, lamp not included. Dimmable with standard incandescent dimmer (not included).

LED: 9W Replaceable source, 120V, CL dimmable, 90+ CRI, 3000°K CCT, 800 lumens, 30,000 hours. Lamp included. (Additional Color Temperatures available, including 3500°K and 4000°K)

DIFFUSER

Shade shall be handcrafted glass of various decors. 10" Dia. x 9.5" H

SUSPENSION

Cord-hung: 10' SVT-type cord, complete with 5" decorative sleeve at the socketholder. Jacket coordinates with metal finish. Plated stamped steel construction. Black, Bronze or Satin Nickel. See next page for multilight options.

Stem-mount: Includes 4 connectable stem sections (3", 6", 12" and 18" lengths) plus telescoping piece for up to 3" adjustment, 10' max. 5" Dia. canopy (with swivel) and stem sections are plated steel. Black, Bronze or Satin Nickel.

*Additional Stem Sections can be ordered under accessories.

MOUNTING

Installs directly to a 4" octagonal ceiling box. Suitable for sloped ceilings.


LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).

Consult factory concerning lower wattage labeling for energy requirements.



BLACK (ROCKYBK) & COPPER (ROCKYCP)

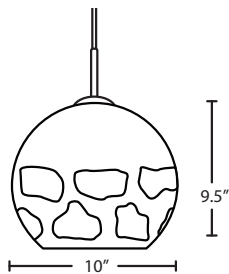

ROCKYWH
WHITE



Project Information:

For ordering information, see next page

All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 5/22




ORDERING:

CONNECTION	SHADE OPTIONS	LAMP OPTIONS	METAL FINISH	OPTIONS
Pendant Fixtures	ROCKYBK Black	(blank) 60W Incan	BK Black	L 15' cord
1JC Dome Canopy	ROCKYCP Copper	LED* 9W LED 120V,	BR Bronze	LW Low
1JT Flat Canopy	ROCKYWH White	dimmable	SN Satin Nickel	wattage labeling

*CCT options available (contact factory)

Stem Fixtures
1TT Flat Canopy

Multi light Cord Fixture
J For Multi light Canopy

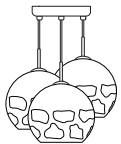


Multilight Canopies Available, see page 11


Ex. 1JT-ROCKYCP-SN
Rocky Glass Pendant, Copper, Satin Nickel Finish, Flat Canopy

MULTIPOINT CANOPY OPTIONS FOR CORD PENDANTS


T33X 3 LIGHT ROUND CANOPY

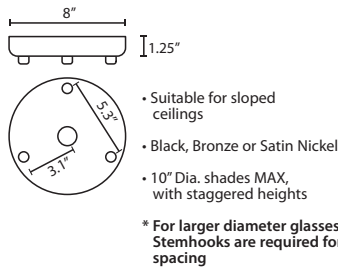


T33XL 3 LIGHT LARGE ROUND CANOPY

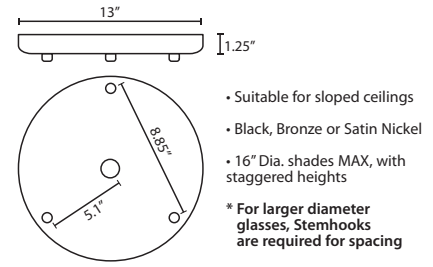


T36X 6 LIGHT ROUND CANOPY

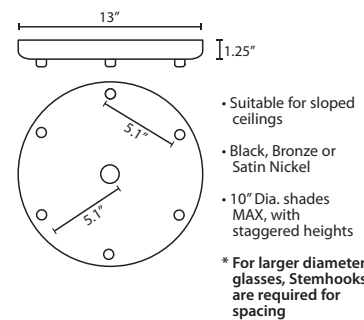


T39X 9 LIGHT ROUND CANOPY

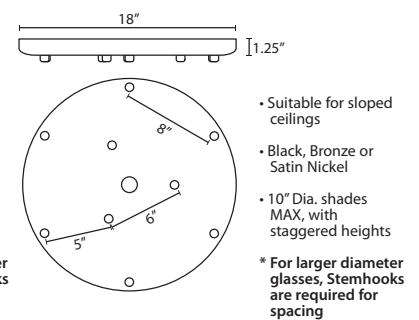


T33V 3 LIGHT BAR CANOPY

 

T34V 4 LIGHT BAR CANOPY

 


T37V 7 LIGHT BAR CANOPY

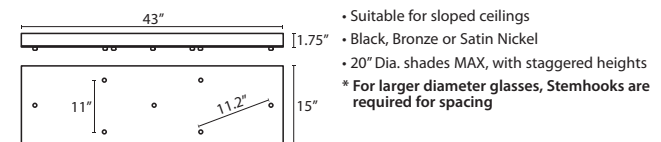


PENDANT OPTIONS:

1JT / 1JC / J CORD-HUNG PENDANT

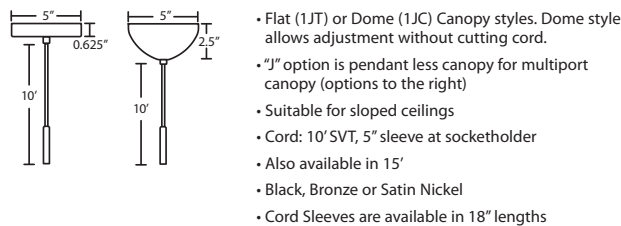

1TT STEM PENDANT

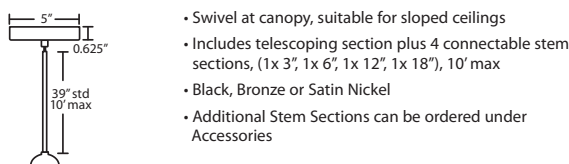

ACCESSORIES:

ADDITIONAL STEM SECTIONS:

Additional connecting stems are available to increase overall length of a Stem Pendant, up to 10' max. Telescoping adjustable section allows up to 3" movement.

T20A-SN, BK or BR	Adj. Section
T203-SN, BK or BR	3" Section
T206-SN, BK or BR	6" Section
T212-SN, BK or BR	12" Section
T218-SN, BK or BR	18" Section

LONGER CORD LENGTHS:

Longer cord length of 15' available. Add an "L" to the end of the item number, i.e. 1JC-169707-SN-L.

LOW WATTAGE LABELING:

Incandescent fixture supplied with 16 watt relamp label. Add an "LW" to the end of the item number, i.e. 1JC-169707-SN-LW.

CORD SLEEVES:

If concealing the cord is desired on a Cord-hung Pendant, order our 0.25" dia. metal sleeves. Each sleeve is 18" long and may be field cut.

T118-BK	Black
T118-BR	Bronze
T118-SN	Satin Nickel

STEMHOOKS:

Suspension hooks allow cord drops to be placed wherever desired. Suitable for sloped ceilings or for greater multilight spacing

T103BK	Black
T103BR	Bronze
T103SN	Satin Nickel

HOW TO ORDER A MULTILIGHT FIXTURE

Order your canopy with the selected 120V multi light pendants (indicated by "B" or "J" prefix) for the complete fixture:

Example: 1x T33X-SN (3 Light Round Canopy)

1x J-ROCKYCP-SN (Rocky Pendant in Copper)

1x J-ROCKYCP-SN (Rocky Pendant in Copper)

1x J-ROCKYCP-SN (Rocky Pendant in Copper)