



SASHA

MINI SCONCES WALL

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

Wall-mounted sconce featuring one handcrafted glass.

LAMPING

Standard: 60W A19 120V incandescent, suitable for dimming, lamp not included.
(Incandescent dimmer is suitable for dimming, not included)

LED: 9W Replaceable LED source, 120V, dimmable, 90+ CRI, 2800°K CCT, 800 lumens, 30,000 hours, lamp included.

DIFFUSER

Shade shall be handcrafted glass of various decors.
Diameter of 6.3125" and height of 5.4375"

CONSTRUCTION

Fixture utilizes die-cast arm assembly and stamped steel canopy (4.75" H), with plated metal finish.

METAL FINISH

Fixture shall be finished in Bronze, Chrome or Satin Nickel.

MOUNTING


Installs directly to a 4" octagonal outlet box. Orient upward or downward, wall-mount only.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



SASHA SHOWN IN GARNET (757241) IN CHROME FINISH

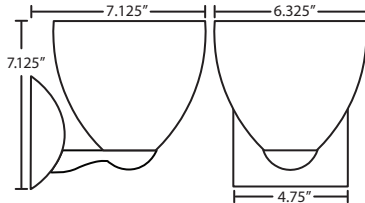

757207
OPAL MATTE



7572MG
MARBLE GRIGIO



757218
AMBER CLOUD



7572HN
HONEY



7572HB
HABANERO




757218
CARRERA



7572CE
CEYLON



757286
BLUE CLOUD

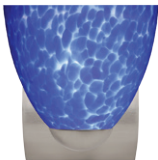

For ordering information, see next page

All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 8/21



ORDERING:

FIXTURE	GLASS OPTIONS	LAMPING OPTIONS	METAL FINISH	OPTIONS
1WZ Sconce	757207 Opal Matte	(blank) 60W A15 or A19	BR Bronze	LW Low Wattage
	757218 Amber Cloud	LED 9W LED 120V,	CR Chrome	labeling
	757219 Carrera	dimmable	SN Satin Nickel	
	757241 Garnet			
	757286 Blue Cloud			
	7572CE Ceylon			
	7572HB Habanero			
	7572HN Honey			
	7572MG Marble Grigio			

Ex. 1WZ-757207-BR

Sasha II Mini Sconce w/ Opal Matte Glass,
Bronze Finish

Project Information: