



# SASHA

VANITIES WALL

location:  
**DAMP**

## SPECIFICATIONS:

### DESCRIPTION

2-4 light vanity luminaires featuring handcrafted glass.

### LAMPING

**Standard:** 60W A15 or A19 120V incandescent, suitable for dimming, lamp not included. *(Incandescent dimmer is suitable for dimming, not included)*

**LED:** 9W Replaceable LED source, 120V, dimmable, 90+ CRI, 3000°K CCT, 800 lumens, 30,000 hours, lamp included.

### DIFFUSER

Shades shall be handcrafted glass of various decors.  
6.325" Dia. x 5.5" H, spaced 7.875" apart on center.

### CONSTRUCTION

Fixture utilizes die-cast arm assembly and stamped steel canopy (4.75" H), with plated metal finish.

### METAL FINISH

Fixture shall be finished in Bronze, Chrome or Satin Nickel.

### MOUNTING

Installs directly to a 4" octagonal outlet box.  
Orient upward or downward, wall-mount only.

### LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



SASHA SHOWN IN CARRERA (757219) IN DOWNWARD ORIENTATION

757207  
OPAL MATTE



7572MG  
MARBLE GRIGIO



757218  
AMBER CLOUD



7572HN  
HONEY



7572HB  
HABANERO




757241  
GARNET



7572CE  
CEYLON



757286  
BLUE CLOUD

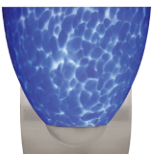

For ordering information, see next page

All dimensions provided are nominal.  
Allowance must be made for dimensional tolerance in handcrafted glasses.




REV 8/21



ORDERING:

FIXTURE	GLASS OPTIONS	LAMPING OPTIONS	METAL FINISH	OPTIONS
1WZ Sconce	757207 Opal Matte	(blank) 60W A15 or A19	BR Bronze	LW Low Wattage
2WZ 2 Light	757218 Amber Cloud	LED 9W LED 120V,	CR Chrome	labeling
3WZ 3 Light	757219 Carrera	dimnable	SN Satin Nickel	
4WZ 4 Light	757241 Garnet			
	757286 Blue Cloud			
	7572CE Ceylon			
	7572HB Habanero			
	7572HN Honey			
	7572MG Marble Grigio			

**Ex. 3WZ-757207-SN**  
 Sasha 3-Light Vanity w/ Opal Matte Glass,  
 Satin Nickel Finish

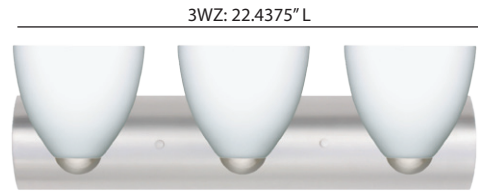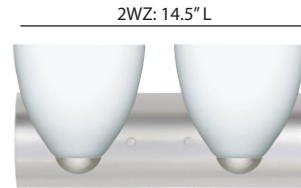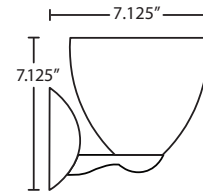

**Project Information:**