



SNAP 5

SCONCES OUTDOOR



SPECIFICATIONS:

DESCRIPTION

Wall-mounted **ADA-compliant** sconce featuring handcrafted glass diffuser.

LAMPING

LED: 10W Replaceable LED source, 120V, CL dimmable, 90+ CRI, 3000°K CCT, 865 lumens, 30,000 hours, lamp included.

DIFFUSER

Diffuser shall be of glass in Glitter/Clear decor. 5.25" Dia. x 3.25" D

CONSTRUCTION

Stamped aluminum fitter is powder coated white or black. Glass secured by stainless steel set screws.

MOUNTING


Installs directly to a 4" octagonal outlet box. 75°C supply wire required for incandescent lamping. Fixture is centered on the outlet box.

LABELS

UL or ETL Listed. Suitable for Wet Locations (interior or exterior use).



SNAP5GL (GLITTER/CLEAR)

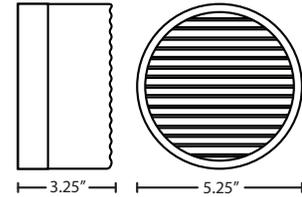


SNAP5GL-LED-BK
GLITTER/CLEAR

ORDERING:

FIXTURE	LAMP OPTIONS	FINISH
SNAP5GL Glitter/Clear	LED 10W LED 865 lumens 3000K	BK Black WH White

Ex. SNAP5GL-LED-WH
Snap 5 LED Outdoor Sconce,
Glitter/Clear Shade, White Finish

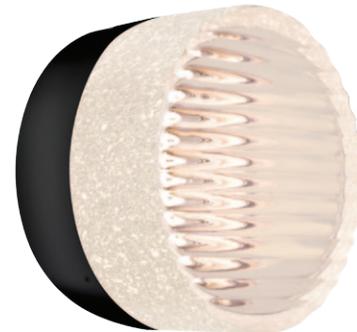

Project Information:

All dimensions provided are nominal. Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 1/22