



SONYA 13 / 17 / 20

FLUSH MOUNT CEILING

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

Flush-mounted round ceiling luminaires, featuring handcrafted glass. Three sizes available.

LAMPING

Standard: 100W low-pressure G9 Halogen 120V lamps, included. Suitable for dimming.

Medium-based: 100W A19 120V incandescent, lamp not included. Dimmable with standard incandescent dimmer (not included).

LED: 11W Replaceable source, 120V, CL dimmable, 90+ CRI, 3000°K CCT, 1100 lumens, 30,000 hours, lamp included.

DIFFUSER

Handcrafted glass diffuser is available in various decors.

Sonya 13 #8417XX: 13" Dia. x 4.375" H

Sonya 17 #8418XX: 17" Dia. x 5.25" H

Sonya 20 #8419XX: 20.875" Dia. x 5.625" H

CONSTRUCTION

Glass diffuser is secured to fitter with "twist-lock" clips. Stamped aluminum fitter is powder coated white.

MOUNTING

Installs directly to a 4" octagonal outlet box, centered on fixture. 90°C supply wire required for incandescent lamping.

LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



SONYA CEILING SHOWN IN GLITTER



Hardware detail

SATIN WHITE



For ordering information, see next page

 
All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 12/18




ORDERING:

Sonya 13 #8417:




GLASS OPTIONS	LAMP OPTIONS	METAL FINISH
841725 13.0" Satin Frost	(blank) 1x 100W G9 Hal	BR Bronze
8417GL 13.0" Glitter	MED 1x 100W A19 Incan	PN Polished Nickel
	LED 1x 11W LED 120V, dimmable	SN Satin Nickel
		WH White

Sonya 17 #8418:

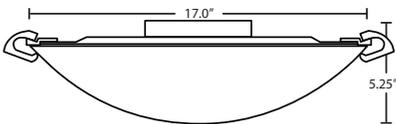

GLASS OPTIONS	LAMP OPTIONS	METAL FINISH
841825 17.0" Satin Frost	(blank) 2x 100W G9 Hal	BR Bronze
8418GL 17.0" Glitter	MED 2x 100W A19 Incan	PN Polished Nickel
	LED 2x 11W LED 120V, dimmable	SN Satin Nickel
		WH White

Sonya 20 #8419:

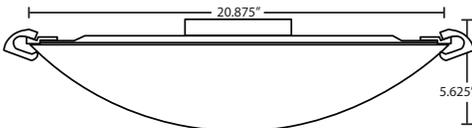

GLASS OPTIONS	LAMP OPTIONS	METAL FINISH
841925 20.875" Satin Frost	(blank) 3x 100W G9 Hal	BR Bronze
8419GL 20.875" Glitter	MED 3x 100W A19 Incan	PN Polished Nickel
	LED 3x 11W LED 120V, dimmable	SN Satin Nickel
		WH White

Ex. **8417GL-SN**
Sonya 13 Ceiling w/ Glitter Glass,
Satin Nickel Clips

Project Information: