



SPEZZA 7

120V PENDANTS

SPECIFICATIONS:

DESCRIPTION

Our industrial styled Spezza pendant, with its artistic display of woven metal rods, offers a look that will easily merge into the recent urban decorating trend. The exposed hardware is designed to be celebrated, and offers perfect synergy when combined with the illuminated exposed light source.

LAMPING

Standard: 100W A19 120V incandescent, lamp not included. Dimmable with standard incandescent dimmer (not included).

LED Filament: 7W Replaceable A19 LED Filament lamp, 120V, CL dimmable, 90+ CRI, 3000°K CCT, 800 lumens, 15,000 hours, lamp included.

DIFFUSER

Shade shall be wireform metal of various decors. 8" Dia. x 7.25" H

SUSPENSION

Cord-hung: 10' SVT-type cord, complete with 5" decorative sleeve at the socketholder. Jacket coordinates with metal finish. Plated stamped steel construction. Black, Bronze or Satin Nickel. See next page for mult light options.

Stem-mount: Includes 4 connectable stem sections (3", 6", 12" and 18" lengths) plus telescoping piece for up to 3" adjustment, 10' max. 5" Dia. canopy (with swivel) and stem sections are plated steel. Black, Bronze or Satin Nickel.

*Additional Stem Sections can be ordered under accessories.

MOUNTING

Installs directly to a 4" octagonal ceiling box. Suitable for sloped ceilings.


LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).

Consult factory concerning lower wattage labeling for energy requirements.



SPEZZA 7 SHOWN IN SATIN NICKEL WITH LED FILAMENT LAMP & BLACK

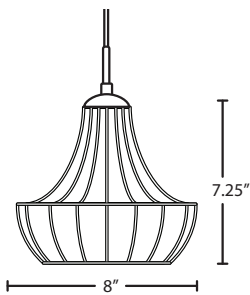

BRONZE



Project Information:

For ordering information, see next page

All dimensions provided are nominal. Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 7/22



ORDERING:

| CONNECTION | SHADE OPTIONS | LAMP OPTIONS | METAL FINISH | OPTIONS |
|-----------------------|------------------------|--|---|---|
| Cord Fixture | SPEZ07 Spezza 7 | (blank) 100W A19 Incan EDIL 7W LED Filament | BK Black BR Bronze SN Satin Nickel | L 15' cord LW Low wattage labeling |
| 1JC 1 Lt. Dome | | | | |
| 1JT 1 Lt. Flat | | | | |

Stem Fixture

1TT 1 Lt. Flat

Multi light Cord Fixture
J For Multi light Canopy

 


Multi light Canopies Available, see page 11

Ex. 1JT-SPEZ07-SN
Spezza 7 Pendant w/ Satin Nickel Finish, Flat Canopy


MULTIPOINT CANOPY OPTIONS FOR CORD PENDANTS

T33X 3 LIGHT ROUND CANOPY



- Suitable for sloped ceilings
- Black, Bronze or Satin Nickel
- 10" Dia. shades MAX, with staggered heights
- * For larger diameter glasses, Stemhooks are required for spacing

 T33XL 3 LIGHT LARGE ROUND CANOPY




- Suitable for sloped ceilings
- Black, Bronze or Satin Nickel
- 16" Dia. shades MAX, with staggered heights
- * For larger diameter glasses, Stemhooks are required for spacing

T36X 6 LIGHT ROUND CANOPY



- Suitable for sloped ceilings
- Black, Bronze or Satin Nickel
- 10" Dia. shades MAX, with staggered heights
- * For larger diameter glasses, Stemhooks are required for spacing

 
T39X 9 LIGHT ROUND CANOPY



- Suitable for sloped ceilings
- Black, Bronze or Satin Nickel
- 10" Dia. shades MAX, with staggered heights
- * For larger diameter glasses, Stemhooks are required for spacing


PENDANT OPTIONS:

1JT / 1JC / J CORD-HUNG PENDANT

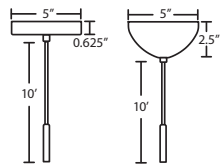

- Flat (1JT) or Dome (1JC) Canopy styles. Dome style allows adjustment without cutting cord.
- "J" option is pendant less canopy for multipoint canopy (options to the right)
- Suitable for sloped ceilings
- Cord: 10' SVT, 5" sleeve at socketholder
- Also available in 15'
- Black, Bronze or Satin Nickel
- Cord Sleeves are available in 18" lengths

 1TT STEM PENDANT



- Swivel at canopy, suitable for sloped ceilings
- Includes telescoping section plus 4 connectable stem sections, (1x 3", 1x 6", 1x 12", 1x 18"), 10' max
- Black, Bronze or Satin Nickel
- Additional Stem Sections can be ordered under Accessories

ACCESSORIES:

ADDITIONAL STEM SECTIONS:

Additional connecting stems are available to increase overall length of a Stem Pendant, up to 10' max. Telescoping adjustable section allows up to 3" movement.

| | |
|--------------------------|--------------|
| T20A-SN, BK or BR | Adj. Section |
| T203-SN, BK or BR | 3" Section |
| T206-SN, BK or BR | 6" Section |
| T212-SN, BK or BR | 12" Section |
| T218-SN, BK or BR | 18" Section |

LONGER CORD LENGTHS:

Longer cord length of 15' available. Add an "L" to the end of the item number, i.e. 1JC-169707-SN-L.

LOW WATTAGE LABELING:

Incandescent fixture supplied with 16 watt relamp label. Add an "LW" to the end of the item number, i.e. 1JC-169707-SN-LW.

CORD SLEEVES:

If concealing the cord is desired on a Cord-hung Pendant, order our 0.25" dia. metal sleeves. Each sleeve is 18" long and may be field cut.


| | |
|----------------|--------------|
| T118-BK | Black |
| T118-BR | Bronze |
| T118-SN | Satin Nickel |

STEMHOOKS:

Suspension hooks allow cord drops to be placed wherever desired. Suitable for sloped ceilings or for greater multilight spacing


| | |
|---------------|--------------|
| T103BK | Black |
| T103BR | Bronze |
| T103SN | Satin Nickel |

 T33V 3 LIGHT BAR CANOPY




- Suitable for sloped ceilings
- Black, Bronze or Satin Nickel
- 20" Dia. shades MAX, with staggered heights
- * For larger diameter glasses, Stemhooks are required for spacing

 T34V 4 LIGHT BAR CANOPY



- Suitable for sloped ceilings
- Black, Bronze or Satin Nickel
- 20" Dia. shades MAX, with staggered heights
- * For larger diameter glasses, Stemhooks are required for spacing

T37V 7 LIGHT BAR CANOPY

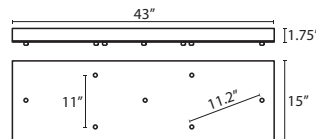

- Suitable for sloped ceilings
- Black, Bronze or Satin Nickel
- 20" Dia. shades MAX, with staggered heights
- * For larger diameter glasses, Stemhooks are required for spacing

HOW TO ORDER A MULTILIGHT FIXTURE

Order your canopy with the selected 120V multi light pendants (indicated by "B" or "J" prefix) for the complete fixture:

Example: 1x T33X-SN (3 Light Round Canopy)

1x J-SPEZ07-SN (Spezza 7 Pendant in Satin Nickel)

1x J-SPEZ07-SN (Spezza 7 Pendant in Satin Nickel)

1x J-SPEZ07-SN (Spezza 7 Pendant in Satin Nickel)