



TAMBURO 16

120V PENDANTS

location:
DAMP

SPECIFICATIONS:

DESCRIPTION

Tamburo is a classic open-ended cylinder of handcrafted European glass, a shape that will stand the test of time.

LAMPING

Standard: 3x100W A19 120V incandescent, lamp not included. Dimmable with standard incandescent dimmer (not included).

LED: 11W Replaceable source, 120V, dimmable, 90+ CRI, 3000°K CCT, 1100 lumens, 30,000 hours. Lamp included. (Additional Color Temperatures available, including 3500°K and 4000°K)

DIFFUSER

Shades shall be handcrafted glass in various decors. Includes frosted glass glare shield. 15.75" Dia. x 7.875" H

Opening sizes: 3x7mm holes.

SUSPENSION

Cable-hung: 3x 10' aircraft-quality stainless steel cable support with 10' AWM-type cord. Jacket tint coordinates with metal finish. 5" Dia. canopy is plated stamped steel. Black, Bronze or Satin Nickel.

Stem-mount: Includes 4 connectable stem sections (3", 6", 12" and 18" lengths) plus telescoping piece for up to 3" adjustment, 10' max. 5" Dia. canopy (with swivel) and stem sections are plated steel. Black, Bronze or Satin Nickel.

*Additional Stem Sections can be ordered under accessories.

MOUNTING

Installs directly to a 4" octagonal ceiling box. Suitable for sloped ceilings.


LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).

Consult factory concerning lower wattage labeling for energy requirements.



TAMBURO 16 SHOWN IN CLEAR STONE (400800) & GLITTER STONE (4008GL)

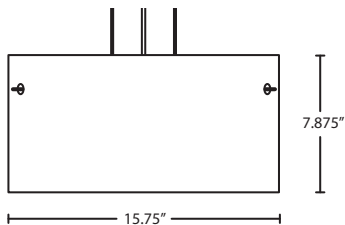

400807
OPAL MATTE



4008GS
STONE GOLD FOIL



4008CS
STONE COPPER FOIL



4008SS
STONE SILVER FOIL



4008KR
CHALK



4008TN
TITAN



4008OK
OAK



4008CH
CHERRY



For ordering information, see next page

All dimensions provided are nominal.
Allowance must be made for dimensional tolerance in handcrafted glasses.

REV 5/22




ORDERING:

CONNECTION -	SHADE OPTIONS -	LAMP OPTIONS -	METAL FINISH -	OPTIONS
3x Cable Fixture	400807 Opal Matte	(blank) 3x 100W A19 Incan	BK Black	L 15' cord
1KV 1 Lt. Flat	4008CH Cherry	LED* 3x 11W LED 120V, dimmable	BR Bronze	LW Low wattage labeling
	4008KR Chalk		SN Satin Nickel	
Stem Fixture	40080K Oak	*CCT options available (contact factory)		
1KT 1 Lt. Flat	4008TN Titan			
	400800 Clear Stone			
	4008CS Stone Copper Foil			
	4008GL Glitter Stone			
	4008GS Stone Gold Foil			
	4008SS Stone Silver Foil			

Ex. 1KV-40080K-SN
Tamburo 16 Pendant w/ Oak Glass,
Satin Nickel Finish


PENDANT OPTIONS:

CABLE-HUNG PENDANT

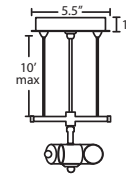

- 3x 10' aircraft-quality stainless steel cable
- 1KV Series: 3x lampholder includes flat glass glare shield
- Cord: 10' AWM-type provided
- Also available in 15'
- Black, Bronze or Satin Nickel

 STEM PENDANT



- Swivel at canopy, suitable for sloped ceilings
- Includes telescoping section plus 4 connectable stem sections, (1x 3", 1x 6", 1x 12", 1x 18"), 10' max
- Black, Bronze or Satin Nickel
- Additional Stem Sections can be ordered under Accessories

ACCESSORIES:

ADDITIONAL STEM SECTIONS:

Additional connecting stems are available to increase overall length of a Stem Pendant, up to 10' max. Telescoping adjustable section allows up to 3" movement.

T20A-SN, BK or BR	Adj. Section
T203-SN, BK or BR	3" Section
T206-SN, BK or BR	6" Section
T212-SN, BK or BR	12" Section
T218-SN, BK or BR	18" Section

LONGER CORD LENGTHS:

Longer cord length of 15' available. Add an "L" to the end of the item number, i.e. 1JC-169707-SN-L.

LOW WATTAGE LABELING:

Incandescent fixture supplied with 16 watt relamp label. Add an "LW" to the end of the item number, i.e. 1JC-169707-SN-LW.

Project Information: