



# WISH

VANITIES WALL

location:  
**DAMP**

## SPECIFICATIONS:

### DESCRIPTION

1-3 light vanity luminaires featuring handcrafted teardrop-shaped shades.

### LAMPING

**Standard:** 60W T10 Medium-based 120V incandescent, suitable for dimming, lamp not included. (*Incandescent dimmer is suitable for dimming, not included*)

**LED Filament:** 4W Replaceable T-shape LED Filament lamp, 120V, dimmable, 2700°K CCT, 430 lumens, 15,000 hours, lamp included.

### DIFFUSER

Shade shall be of glass either clear or clear with a high tech semi-transparent metallic treatment. 3.125" Dia. x 6.375" H, spaced 8" apart on center.

### CONSTRUCTION

Fixture utilizes gooseneck arm assembly and stamped steel canopy (6" H), with plated metal finish.

### METAL FINISH

Fixture shall be finished in Black.

### MOUNTING

Installs directly to a 4" octagonal outlet box. Orient upward or downward, wall-mount only.

### LABELS

UL or ETL Listed. Suitable for Damp Locations (interior use only).



SMOKE/CLEAR (WISHSM)

WISHCL  
CLEAR

WISHAM  
AMBER/CLEAR

WISHBL  
BLUE/CLEAR



For ordering information, see next page

All dimensions provided are nominal.  
Allowance must be made for dimensional tolerance in handcrafted glasses.


REV 1/22



ORDERING:

FIXTURE	GLASS OPTIONS	LAMP OPTIONS	METAL FINISH
1WG 5.9" L Sconce	WISHAM Amber/Clear	(blank) 60W T10 Incan	BK Black
2WG 12.25" L 2-Light	WISHBL Blue/Clear	EDIL 4W LED Filament	
3WG 20" L 3-Light	WISHCL Clear		
	WISHSM Smoke/Clear		

Ex. 2WG-WISHCL-BK  
Wish Vanity, Clear Glass,  
Black Finish

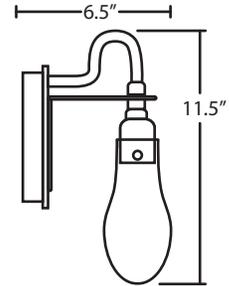

1WG: 5.9" L



2WG: 12.25" L



3WG: 20" L



Project Information: