



# BEVERAGE-AIR

|                 |            |
|-----------------|------------|
| Project: _____  | AIA# _____ |
| Item: _____     |            |
| Location: _____ | SIS# _____ |
| Approved: _____ |            |

## UCR UNDERCOUNTER

UCR34HC Undercounter Refrigerator  
Hydrocarbon Series

**MODELS:**  
UCR34HC

UCR34HC Undercounter Refrigerator: Food Prep Series



UCR34HC

**3 Year Parts/Labor Warranty**  
**Additional 2 Year Compressor Warranty**

### CABINET CONSTRUCTION

- Stainless steel front, sides, top, doors, (*galvanized steel back & bottom*)
- Interior liner is made of corrosion resistant aluminum
- Full electronic control
- Undercounter feature a 1/2" thick sub-top
- Interior thermometer is standard
- Self-closing doors with 120° stay-open feature, on cartridge style hinges
- Easy door removal for service and cleaning
- Magnetic gasket attached to each door for positive seal
- Painted aluminum door handles
- 6" Casters, two (2) with brakes standard
- Two epoxy-coated steel wire shelves standard
- Field reversible doors
- Maintains product temperature between 36°F and 38°F

### OPTIONS & ACCESSORIES

- ☐ Stainless steel back and grille
- ☐ Stainless steel interior
- ☐ Right or left hinged door
- ☐ Locks (solid doors only)
- ☐ Wire shelf divider
- ☐ 3" Casters or 6" legs
- ☐ Low profile casters
- ☐ Remote option

### REFRIGERATION SYSTEM

- Refrigeration system uses R290 refrigerant to comply with all environmental concerns
- Automatic, non-electric defrost
- Epoxy coated evaporator coil



3779 Champion Blvd., Winston-Salem, NC 27105  
1-888-845-9800 Fax: 1-336-245-6453  
Beverage-Air.com sales@bevair.com




# BEVERAGE-AIR

| MODEL                              | UCR34HC                   |
|------------------------------------|---------------------------|
| <b>EXTERNAL DIMENSIONAL DATA</b>   |                           |
| Width Overall                      | 34"                       |
| Depth Overall with Handle & Bumper | 24 5/8"                   |
| Height Overall with 6" casters     | 31 1/8"                   |
| Number of Doors                    | 2                         |
| Depth with Door Open 90°           | 38 1/8"                   |
| Door Opening (in)                  | 13 1/8" x 18"             |
| <b>INTERNAL DIMENSIONAL DATA</b>   |                           |
| NET Capacity (cubic ft.)           | 5.96                      |
| Internal Width Overall (in)        | 30"                       |
| Internal Depth Overall (in)        | 16 3/8"                   |
| Internal Depth Useable (in)        | Upper 11"<br>Lower 8 1/4" |
| Internal Front Height Overall (in) | 19 1/2"                   |
| Internal Back Height Useable (in)  | 12 1/2"                   |
| Number of Shelves                  | 2                         |
| <b>ELECTRICAL DATA</b>             |                           |
| Full Load Amperes 115/60/1         | 2.0                       |
| <b>REFRIGERATION DATA</b>          |                           |
| Horsepower                         | 1/10                      |
| Capacity (BTU/Hr)*                 | 1110                      |
| <b>WEIGHT DATA</b>                 |                           |
| Gross Weight (Crated lbs)          | 167 lbs                   |
| Height - Crated                    | 35"                       |
| Width - Crated                     | 37"                       |
| Depth - Crated                     | 23"                       |

## Undercounter Refrigerators

Models: UCR34HC

### Model Views

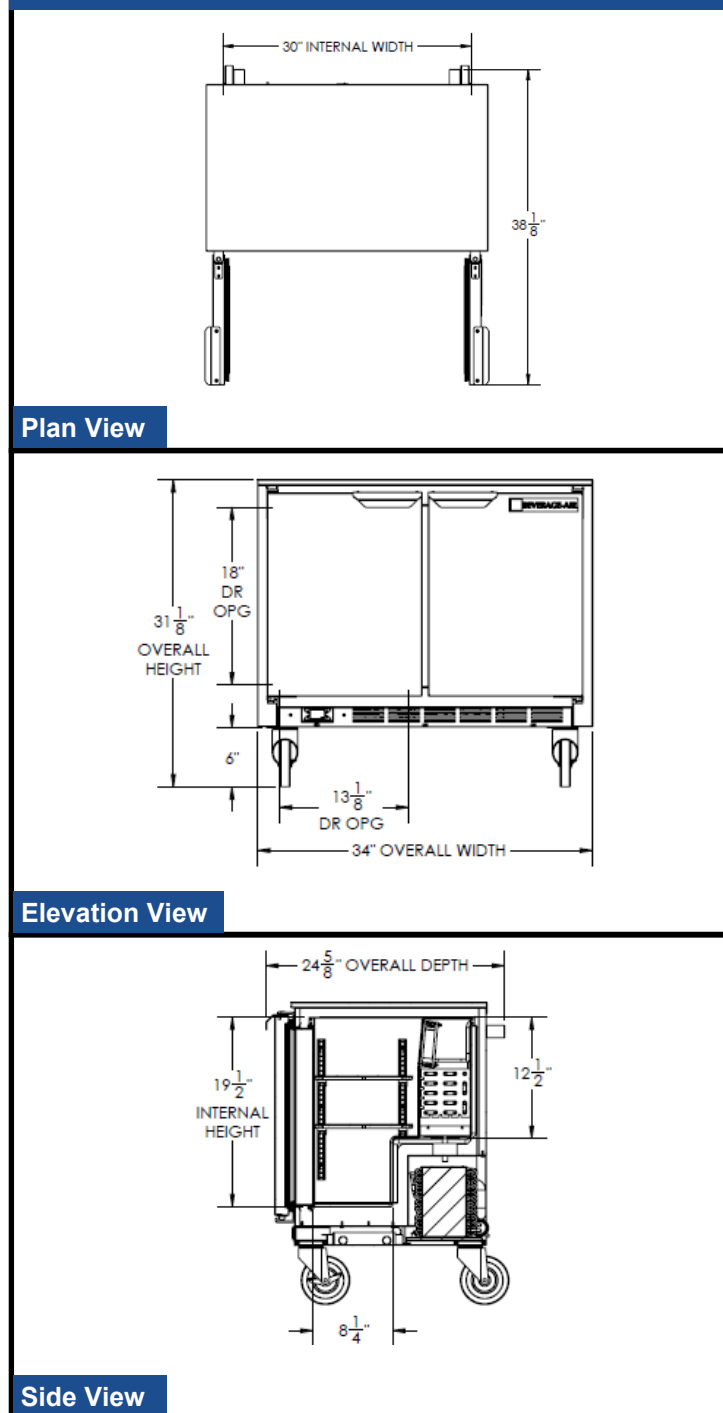

### ELECTRICAL CONNECTION



115/60/1  
NEMA-5-15P

Units pre-wired at  
factory and include 8'  
long cord and plug set.



an Ali Group Company



The Spirit of Excellence

3779 Champion Blvd., Winston-Salem, NC 27105  
1-888-845-9800 Fax: 1-336-245-6453  
Beverage-Air.com sales@bevair.com