


# globe

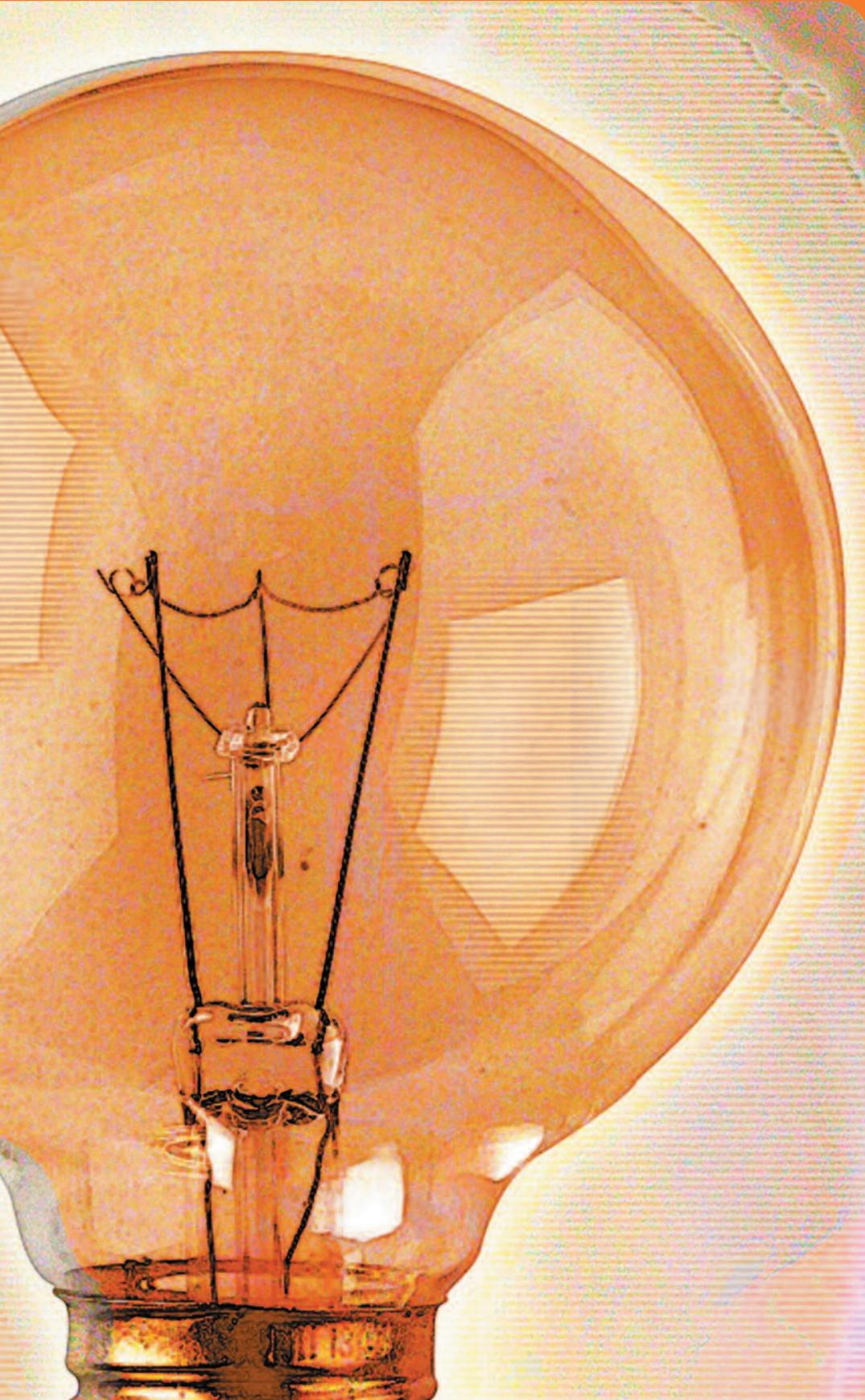

- 30 G-9, G-12**  
Candelabra Base
- 31 G-16½**  
Candelabra Base
- 32 G-14, G-16½, G-19**  
Medium Base
- 33 G-25**  
Medium Base
- 34 G-30, G-40**  
Medium Base

# G-9, G-12 Candelabra Base

- 130 Volt
- G-9 (1 1/8" diameter)
- G-12 (1 1/2" diameter)



**Matte White**  
10G9WH



**White**  
10G12WH  
15G12WH  
25G12WH



**Clear**  
10G12CL  
15G12CL  
25G12CL  
40G12CL



**Transparent Red**  
10G12R

For *KRystal Touch*<sup>®</sup> KRYPTON BULB G-11, see page 69.

**COLORS**



**Amber**  
10G12A



**Blue**  
10G12B



**Green**  
10G12G



**Pink**  
10G12P



**Red**  
10G12R

WATTS	BULB TYPE	BASE	ITEM NUMBER	ORDERING CODE	VOLTS	FINISH	INNER PK/ MASTER CTN	AVERAGE HOURS	LUMENS	M. O. L.
10	G9	Cand.	300005	10G9WH	130	Matte White	25/500	2500	50	1 7/8"
			300010	10G12WH	130	White	25/500	2500	41	2 3/8"
	G12	Cand.	301010	10G12CL	130	Clear	25/500	2500	58	2 3/8"
			302010	10G12A	130	Transp. Amber	25/500	2500	----	2 3/8"
			303010	10G12B	130	Transp. Blue	25/500	2500	----	2 3/8"
			304010	10G12G	130	Transp. Green	25/500	2500	----	2 3/8"
			305010	10G12P	130	Transp. Pink	25/500	2500	----	2 3/8"
306010	10G12R	130	Transp. Red	25/500	2500	----	2 3/8"			
15	G12	Cand.	300015	15G12WH	130	White	25/500	2500	85	2 3/8"
			301015	15G12CL	130	Clear	25/500	2500	105	2 3/8"
25	G12	Cand.	300025	25G12WH	130	White	25/500	2500	175	2 3/8"
			301025	25G12CL	130	Clear	25/500	2500	180	2 3/8"
40	G12	Cand.	301040	40G12CL	130	Clear	25/500	2500	325	2 3/8"

Specifications based on 120V line.



# G-16<sup>1</sup>/<sub>2</sub>

## Candelabra Base



- 120 & 130 Volt
- 2" diameter
- Vanity bulb

globe



**Matte White**  
**130V**  
15G16WHF  
25G16WHF  
40G16WHF  
60G16WHF



**Clear**  
**120V      130V**  
15G16CL2    15G16CL3  
25G16CL2    25G16CL3  
40G16CL2    40G16CL3  
60G16CL2    60G16CL3



**White**  
**120V      130V**  
15G16WH2    15G16WH3  
25G16WH2    25G16WH3  
40G16WH2    40G16WH3  
60G16WH2    60G16WH3

For Half Chrome G-16<sup>1</sup>/<sub>2</sub>, see page 53.

For *KRystal Touch*<sup>®</sup> KRYPTON BULB G-16<sup>1</sup>/<sub>2</sub>, see page 69.

WATTS	BULB TYPE	BASE	ITEM NUMBER	ORDERING CODE	VOLTS	FINISH	INNER PK/ MASTER CTN	AVERAGE HOURS	LUMENS	M. O. L.
15	G16 <sup>1</sup> / <sub>2</sub>	Cand.	310115	15G16WH3	130	White	25/500	3000	95	3"
			391015	15G16WH2	120	White	25/500	2500	100	3"
			310015	15G16WHF	130	Matte White	25/500	3000	73	3"
			311015	15G16CL3	130	Clear	25/500	3000	102	3"
			391115	15G16CL2	120	Clear	25/500	2500	105	3"
25	G16 <sup>1</sup> / <sub>2</sub>	Cand.	310125	25G16WH3	130	White	25/500	3000	155	3"
			391025	25G16WH2	120	White	25/500	2500	168	3"
			310025	25G16WHF	130	Matte White	25/500	3000	150	3"
			311025	25G16CL3	130	Clear	25/500	3000	160	3"
			391125	25G16CL2	120	Clear	25/500	2500	175	3"
40	G16 <sup>1</sup> / <sub>2</sub>	Cand.	310140	40G16WH3	130	White	25/500	3000	320	3"
			391040	40G16WH2	120	White	25/500	2500	335	3"
			310040	40G16WHF	130	Matte White	25/500	3000	300	3"
			311040	40G16CL3	130	Clear	25/500	3000	325	3"
			391140	40G16CL2	120	Clear	25/500	2500	340	3"
60	G16 <sup>1</sup> / <sub>2</sub>	Cand.	310160	60G16WH3	130	White	25/500	3000	560	3"
			391060	60G16WH2	120	White	25/500	2500	580	3"
			310060	60G16WHF	130	Matte White	25/500	3000	530	3"
			311060	60G16CL3	130	Clear	25/500	3000	540	3"
			391160	60G16CL2	120	Clear	25/500	2500	615	3"

Specifications based on 120V line.



# G-14, G-16½, G-19

## Medium Base

- 125 & 130 Volt
- G-14 (1¾" diameter)
- G-16½ (2" diameter)
- G-19 (2⅜" diameter)

**EASILY FITS  
IN MEDICINE  
CABINETS**



**G-14 (E27) Frost**  
40G14F



**G-16½ White**  
25G16EWH  
40G16EWH  
60G16EWH



**G-16½ Clear**  
25G16ECL  
40G16ECL  
60G16ECL



**G-19 White**  
25G19WH  
40G19WH  
60G19WH



**G-19 Clear**  
25G19CL  
40G19CL  
60G19CL

For LED G-16 & G-19, see page 156.

WATTS	BULB TYPE	BASE	ITEM NUMBER	ORDERING CODE	VOLTS	FINISH	INNER PK/ MASTER CTN	AVERAGE HOURS	LUMENS	M. O. L.
25	G16½	Med.	310225	25G16EWH	125	White	25/250	3000	160	2 7/8"
			311225	25G16ECL	125	Clear	25/250	3000	170	2 7/8"
	G19	Med.	320025	25G19WH	125	White	25/250	3000	160	3 1/2"
			321025	25G19CL	125	Clear	25/250	3000	175	3 1/2"
40	G14	E27	307040	40G14F	130	Frost	25/250	1000	600	2 3/4"
	G16½	Med.	310240	40G16EWH	125	White	25/250	3000	310	2 7/8"
			311240	40G16ECL	125	Clear	25/250	3000	330	2 7/8"
	G19	Med.	320040	40G19WH	125	White	25/250	3000	325	3 1/2"
321040			40G19CL	125	Clear	25/250	3000	340	3 1/2"	
60	G16½	Med.	310260	60G16EWH	125	White	25/250	3000	615	2 7/8"
			311260	60G16ECL	125	Clear	25/250	3000	650	2 7/8"
	G19	Med.	320060	60G19WH	125	White	25/250	3000	550	3 1/2"
			321060	60G19CL	125	Clear	25/250	3000	550	3 1/2"

Specifications based on 120V line.



# G-25

## Medium Base



- 120 & 130 Volt
- 3 1/8" diameter
- Vanity bulb
- Long Life

globe



Clear

<b>120V</b>	<b>130V</b>
25G25CL2	25G25CL3
40G25CL2	40G25CL3
60G25CL2	60G25CL3
100G25CL2	100G25CL3



White

<b>120V</b>	<b>130V</b>
25G25WH2	25G25WH3
40G25WH2	40G25WH3
60G25WH2	60G25WH3
100G25WH2	100G25WH3

For True Daylight G-25, see page 50.

For Half Chrome G-25, see page 53.

For Energy Wiser® CFL G-25, see page 119.

WATTS	BULB TYPE	BASE	ITEM NUMBER	ORDERING CODE	VOLTS	FINISH	INNER PK/ MASTER CTN	AVERAGE HOURS	LUMENS	M. O. L.
25	G25	Med.	330025	25G25WH3	130	White	24/120	3000	160	4 3/8"
			393002	25G25WH2	120	White	24/120	2500	180	4 3/8"
			331025	25G25CL3	130	Clear	24/120	3000	180	4 3/8"
			393102	25G25CL2	120	Clear	24/120	2500	185	4 3/8"
40	G25	Med.	330040	40G25WH3	130	White	24/120	3000	290	4 3/8"
			393004	40G25WH2	120	White	24/120	2500	360	4 3/8"
			331040	40G25CL3	130	Clear	24/120	3000	320	4 3/8"
			393104	40G25CL2	120	Clear	24/120	2500	400	4 3/8"
60	G25	Med.	330060	60G25WH3	130	White	24/120	3000	480	4 3/8"
			393006	60G25WH2	120	White	24/120	2500	630	4 3/8"
			331060	60G25CL3	130	Clear	24/120	3000	530	4 3/8"
			393106	60G25CL2	120	Clear	24/120	2500	675	4 3/8"
100	G25	Med.	330100	100G25WH3	130	White	24/120	3000	975	4 3/8"
			393010	100G25WH2	120	White	24/120	2500	1150	4 3/8"
			331100	100G25CL3	130	Clear	24/120	3000	1150	4 3/8"
			393110	100G25CL2	120	Clear	24/120	2500	1230	4 3/8"

Specifications based on 120V line.



# G-30, G-40 Medium Base

globe

- 125 Volt
- G-30 (3<sup>3</sup>/<sub>4</sub>" diameter)
- G-40 (5" diameter)
- Vanity bulb
- Long Life



**G-30 Clear**  
25G30CL  
40G30CL  
60G30CL  
100G30CL

**G-30 White**  
25G30WH  
40G30WH  
60G30WH  
100G30WH



**G-40 White**  
25G40WH  
40G40WH  
60G40WH  
75G40WH  
100G40WH  
150G40WH

**G-40 Clear**  
25G40CL  
40G40CL  
60G40CL  
100G40CL  
150G40CL

For Half Chrome G-40, see page 53.  
For Energy Wiser® CFL G-30, see page 119.

WATTS	BULB TYPE	BASE	ITEM NUMBER	ORDERING CODE	VOLTS	FINISH	INNER PK/ MASTER CTN	AVERAGE HOURS	LUMENS	M. O. L.
25	G30	Med.	340025	25G30WH	125	White	12/96	3000	175	5 1/8"
			341025	25G30CL	125	Clear	12/96	3000	180	5 1/8"
	G40	Med.	350025	25G40WH	125	White	12/24	3000	160	6 3/4"
			351025	25G40CL	125	Clear	12/24	3000	180	6 3/4"
40	G30	Med.	340040	40G30WH	125	White	12/96	3000	355	5 1/8"
			341040	40G30CL	125	Clear	12/96	3000	385	5 1/8"
	G40	Med.	350040	40G40WH	125	White	12/24	3000	335	6 3/4"
			351040	40G40CL	125	Clear	12/24	3000	355	6 3/4"
60	G30	Med.	340060	60G30WH	125	White	12/96	3000	640	5 1/8"
			341060	60G30CL	125	Clear	12/96	3000	655	5 1/8"
	G40	Med.	350060	60G40WH	125	White	12/24	3000	535	6 3/4"
			351060	60G40CL	125	Clear	12/24	3000	565	6 3/4"
75	G40	Med.	350075	75G40WH	125	White	12/24	3000	740	6 3/4"
100	G30	Med.	340100	100G30WH	125	White	12/96	3000	950	5 1/8"
			341100	100G30CL	125	Clear	12/96	3000	1045	5 1/8"
	G40	Med.	350100	100G40WH	125	White	12/24	3000	950	6 3/4"
			351100	100G40CL	125	Clear	12/24	3000	990	6 3/4"
150	G40	Med.	350150	150G40WH	125	White	12/24	3000	1655	6 3/4"
			351150	150G40CL	125	Clear	12/24	3000	1735	6 3/4"

Specifications based on 120V line.

