




SKU # MS-U30LEDC37.5-W

Part # 1003223

Description

37.5in Marine LED Custom Accent Bar (White) - USA Made Race Sport Lighting

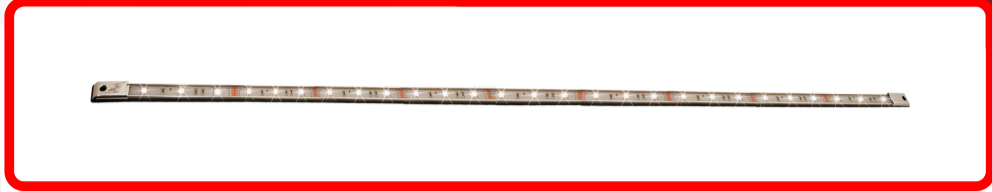

Product Information

Race Sport Lighting's Ultra Series LED accent bars are a durable, ultra-bright lighting solution, ready to take a beating in any exterior automotive lighting application • 37.5" Long • Polished aluminum channel with chrome tips • Great for all exterior applications like truck bed lighting or courtesy lights • Mounts with 3M tape or screw-mount metal channel • IP68 Waterproof Rated • 30 LEDs/m (1 1/4" spacing) or 60 LEDs/m (5/8" spacing) • High lumen output with low heat • Wide dispersion of light • 1 Year Warranty

Categories Marine Sport Lighting, Interior/Exterior Accent LED, Marine

Sub-Categories Marine Accent LED, Extreme Series Accent Bars, LED Accent Lighting Interior

UPC 811712027021

Unit of Measure EA

Related Skus:

Cross Sell Skus:

Condition New
Manufacturer Marine Sport Lighting
EZ Category Marine Accent LED

Harmonization Code 8512.20.2080
Universal YES
Life Expectancy

SEMA Product Marine All-Around Light
Part Type ID 57170

Reverse Polarity Marine All-Around Light
Operating Voltage
Current Draw

Wattage
Chip Type
IP Rating
LUX

Est. Labor	Hours		
Gross Weight	0.40	Width	4.50
Net Weight	0.40	Height	40.50
DIM Weight	0.33	Depth	0.25

Kelvin (ColorTemperature) White
Universal or Vehicle Specific Universal

Made In China
Warranty 1 year
Lumens
Beam Pattern

Prop 65 WARNING: This product can expose you to chemicals, which are known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov