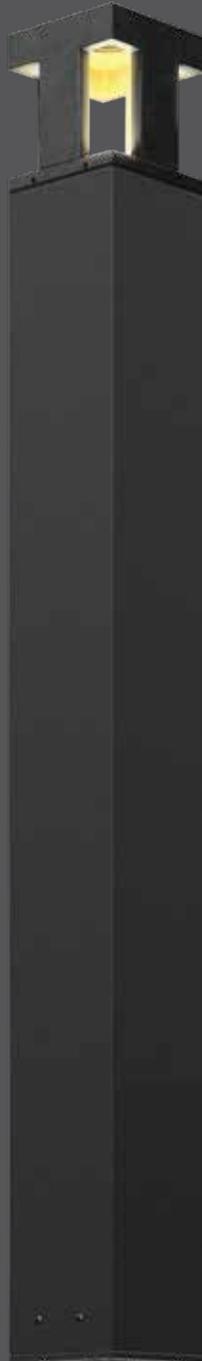

LED Bollard

Our LED bollard will complete every project with style. Providing 7W of powerful light, flexibility and functionality are at your fingertips.



Model	Height	Watts	Delivered lumens	LED lumens	CRI	Color °T	Voltage
LEDPATH003D-24	24"	7 W	180 lm	700 lm	90	3000 K	120 V
LEDPATH003D-30	30"	7 W	180 lm	700 lm	90	3000 K	120 V
LEDPATH003D-36	36"	7 W	180 lm	700 lm	90	3000 K	120 V

Specifications

Over 50,000 hours of service life
 "X" shaped lighting pattern
 Low power consumption
 Available in total height of: 24, 30 and 36"
 Superior color consistency
 Integrated dimmable driver
 Anchor bolts included
 Suitable for wet locations
 Refer to website for dimmer compatibility
 Ideal operating temperature:
 -20° to 40° C
 5-year warranty

Finish

● **BK** Black

Order example

LEDPATH003D-36-BK
 Dimmable LEDPATH003D LED Bollard with a total height of 36" in a black finish

Note

Other Color °T and Finishes available, but may require MOQ's and longer lead times. Please contact your DALs representative for more information.

LEDPATH003D

