

# Save Time and Money!

## One tool for many sizes!



# Multi-Step Drills




Drillco's multi-step drills are designed for all sheet metals up to 5/32" thick. Creates clean, round, burr free holes in multiple sizes with just one tool!

**Spiral Flute Design** allows for a faster and smoother cutting action

**Up to 13 Sizes** with one drill. Save time and money!

**1/4" Quick Change Hex Shank** is impact ready and easily fits into any power drill/driver

**118° Split Point** reduces 'walking'

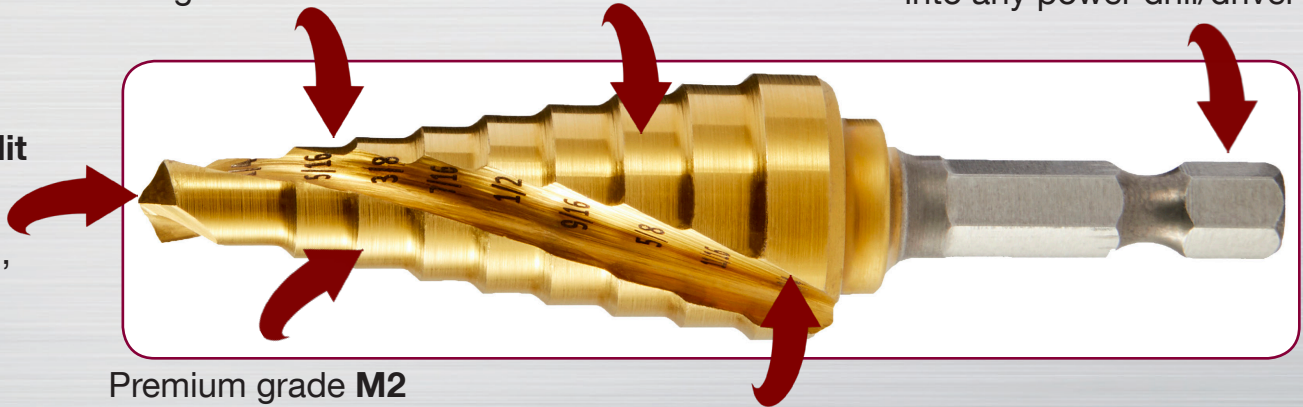

Premium grade M2 High Speed Steel construction

**TiN Coating** adds a protective layer that deflects heat, leading to longer tool life



**Individually Blister packed** for easy display!



**3pc Set**



Combine with Drillco's Heavy-Duty Drilling and Tapping Fluid for optimal performance!

Tool#	Description	4700SE EDP No.
1	13 Steps: 1/8" to 1/2"	895A001
2	9 Steps: 1/4" to 3/4"	895A002
3	12 Steps: 3/16" to 7/8"	895A003
4	13 Steps: 1/4" to 1.1/8"	895A004
SET	3pc Set: Tools #1 - #3	895SET

**Call or email us for more details!**

**800-851-3821**

**sales@drillco-inc.com**