

RECLAIM® ACRYLIC SNEEZE GUARD CUBICLE WALL EXTENDER Clamp-On

Product Specifications

| | |
|-----------------------------|--|
| Item Number | DIVWT |
| Panel Material | Clear acrylic |
| Panel Thickness | 1/4" |
| Clamp Material | Powder-coated aluminum and steel |
| Clamp Type | Hand-adjustable top clamp (tool free attachment to cubicle wall) |
| Clamp Adjustment Range | 1.13" to 2.13" |
| Required Tools for Assembly | Allen wrench (included) |
| Includes | 1 panel and 2 or 3 top clamps (see chart on page 2) |
| Weights and Dimensions | See chart on page 2 |
| Cleaning | Clean with a microfiber cloth and a solution of mild dish soap and water or commercial plastic cleaners rated safe for use on acrylics.* |
| Marker Compatibility | Water-soluble dry-erase markers only** |
| Warranty | 5 year limited warranty |



To Order, Call Your Sales Representative
or 800-323-4656



 
DIVWT-CLAMP



DIVWT-2424C




DIVWT-3024C



DIVWT-4824C




DIVWT-6024C

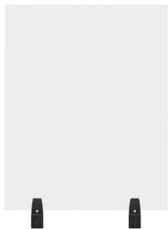

DIVWT-2430C



 DIVWT-3030C



DIVWT-4830C



DIVWT-6030C

DIVWT – SPEC SHEET

| Product # | Product Description | Height | Width | Panel Color | # of Clamps | Shipping Method | Box Length | Box Width | Box Height | Shipping Weight | Panel Weight | |
|-------------|--|--------|-------|-------------|-------------|-----------------|------------|-----------|------------|-----------------|--------------|-----------|
| DIVWT-2430C | 24" x 30" Clear Acrylic Divider w/ 2 Divider Wall Top Clamps | 30" | 24" | Clear | 2 | Ground | 33" | 26" | 2" | 13 lbs. | 6.1 lbs. | |
| DIVWT-3030C | 30" x 30" Clear Acrylic Divider w/ 2 Divider Wall Top Clamps | | 30" | | | | 34" | 32" | 2" | 15 lbs. | 7.7 lbs. | |
| DIVWT-4830C | 48" x 30" Clear Acrylic Divider w/ 2 Divider Wall Top Clamps | | 48" | | | | 52" | 32" | 2" | 23 lbs. | 12.2 lbs. | |
| DIVWT-6030C | 60" x 30" Clear Acrylic Divider w/ 3 Divider Wall Top Clamps | | 60" | | | | 62" | 32" | 2" | 29 lbs. | 15.3 lbs. | |
| DIVWT-2424C | 24" x 24" Clear Acrylic Divider w/ 2 Divider Wall Top Clamps | 24" | 24" | | 2 | | Ground | 28" | 26" | 2" | 11 lbs. | 4.9 lbs. |
| DIVWT-3024C | 30" x 24" Clear Acrylic Divider w/ 2 Divider Wall Top Clamps | | 30" | | | | | 34" | 26" | 2" | 13 lbs. | 6.1 lbs. |
| DIVWT-4824C | 48" x 24" Clear Acrylic Divider w/ 2 Divider Wall Top Clamps | | 48" | | | | | 52" | 26" | 2" | 19 lbs. | 9.8 lbs. |
| DIVWT-6024C | 60" x 24" Clear Acrylic Divider w/ 3 Divider Wall Top Clamps | | 60" | | | | | 64" | 26" | 2" | 24 lbs. | 12.2 lbs. |

IMPORTANT WARNINGS:

***Proper Care and Cleaning of Acrylic – PLEASE READ BEFORE INSTALLING:** Acrylic sheeting can be damaged by harsh solvents and cleaners. Only use cleaning products labeled “commercial plastic cleaners”, or mild soap and water to remove dirt and debris. When applying the cleaner, use a non-abrasive lint-free or microfiber cloth that won't scratch the surface. Never use products containing ammonia, acetone, carbon tetrachloride, scouring compounds, alcohol, bleach, aromatics, or gasoline. Chemical glass cleaners (even if they are environmentally friendly, organic, or non-scented) are also not to be used. All solvents need to be wiped clean with fresh water and blotted dry to reduce and prevent water spotting. Failure to adhere to the above guidelines can cause yellowing, cracks, and scratches in acrylic sheeting and may give the surface a frosted appearance. It will also void the Limited Warranty – our Limited Warranty does not apply to any damage caused by or the result of improper cleaning, handling, installation, operation, maintenance, pressure washing, accident, fire, natural disaster, explosion, abuse, vandalism, chlorine, chemicals from sprinkler systems, or other external forces. This warranty shall be null and void if any harmful solvents are used to clean.

****Use of Dry-Erase Markers:** Water-soluble dry-erase markers are safe for use on these acrylic panels. Other forms of dry-erase markers are not recommended because they will be difficult to erase and could possibly leave stains and ghosting.