




**PRODUCT DESCRIPTION**

Heavy faceted glass fonts are lined with Borosilicate that sparkles while illuminated by the LED G9 lamps which are included. Polished Chrome metal, contribute to the clean and crisp contemporary design.

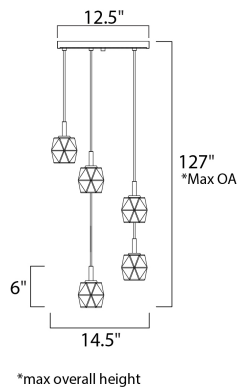

**MEASUREMENTS**

DIMENSION : 14.5" L x 14.5" W x 6" H  
 MAX OAH : 127" OAH  
 CANOPY : 12.5" W x 1" H x 12.5" L  
 HANGING WEIGHT : 12.32 lb

**LAMPING**

INPUT VOLTAGE : 120V  
 LUMENS : 1,400 Rated  
 BULB : 5 x 4W LED G9 , 20W Total  
 BULB INCLUDED : (Included)  
 DIMMABLE : Triac CL  
 CRI : 80+ CRI  
 COLOR\_TEMP : 3000K

**FINISHES OPTION**

 Polished Chrome

**GLASS**

Heavy Faceted 82

**MATERIAL**

Steel

**RATINGS**

cETLus  
 Dry Location



**ADDITIONAL**

ADJUSTABLE  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



**WESTERN DISTRIBUTION CENTER (HEADQUARTER)**  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746  
**EASTERN DISTRIBUTION CENTER**  
 4200 SHIRLEY DR. | ATLANTA, GA 30336  
 P. 626.956.4200 | F. 626.956.4225 | et2online.com