




PRODUCT DESCRIPTION

Rectangular Beveled Crystals are banded together to form soft square cylinders which are illuminated by LED that creates a brilliant lighting effect. Some items include metal chassis of Black which frame the crystal for a beautiful silhouette.

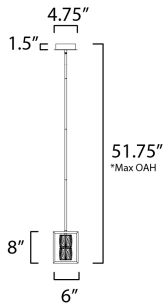

*max overall height

MEASUREMENTS

DIMENSION : 6" L x 6" W x 8" H
MAX OAH : 51.75" OAH
CANOPY : 4.75" W x 1.5" H x 4.75" L
HANGING WEIGHT : 5.15 lb

LAMPING

INPUT VOLTAGE : 120V
LUMENS : 715 Rated (310 Del.)
BULB : 1 x 6.5W LED PCB Integrated , 6W Total
BULB INCLUDED : (Integrated)
DIMMABLE : Triac CL or ELV
CRI : 90+ CRI
COLOR_TEMP : 3000K

FINISHES OPTION

Black

GLASS

Crystal 20

MATERIAL

Steel, Crystal, Stainless Steel

RATINGS

cETLus
Dry Location



ADDITIONAL

ADJUSTABLE
SLOPE: 70
RATED LIFE 25000 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



Contemporary
Lighting™

WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | et2online.com