




**PRODUCT DESCRIPTION**

Rectangular Beveled Crystals are banded together to form soft square cylinders which are illuminated by LED that creates a brilliant lighting effect. Some items include metal chassis of Black which frame the crystal for a beautiful silhouette.

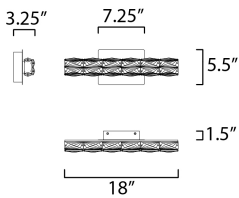


**MEASUREMENTS**

DIMENSION : 18" L 5.5" H x 3.25" Ext  
 BACK PLATE : 4.75" W x 1.5" H x 9" HCO  
 HANGING WEIGHT : 4.25 lb

**LAMPING**

INPUT VOLTAGE : 120V  
 LUMENS : 1,540 Rated (985 Del.)  
 BULB : 1 x 15W LED PCB Integrated , 15W Total  
 BULB INCLUDED : (Integrated)  
 DIMMABLE : Triac CL or ELV  
 CRI : 90+ CRI  
 COLOR\_TEMP : 3000K  
 LIGHTING\_DIRECTION : Omni

**FINISHES OPTION**

 Polished Chrome

**GLASS**

Crystal 20

**MATERIAL**

Steel, Crystal, Stainless Steel

**RATINGS**

cETLus  
 Damp Location  
 ADA



**ADDITIONAL**

INSTALL UP/DOWN: All  
 RATED LIFE 25000 Hours  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



**WESTERN DISTRIBUTION CENTER (HEADQUARTER)**  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746  
**EASTERN DISTRIBUTION CENTER**  
 4200 SHIRLEY DR. | ATLANTA, GA 30336  
 P. 626.956.4200 | F. 626.956.4225 | et2online.com