




PRODUCT DESCRIPTION

With formed metal spheres of Polished Chrome framing multifaceted crystal jewelry, the Brilliant Collection adds a touch of contemporary elegance to any design space. The illumination of xenon lamps reflecting through the crystal offers added brilliance by creating a spectrum of color.

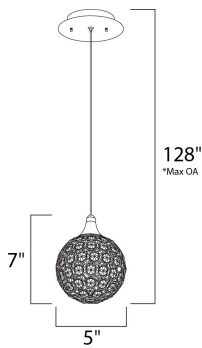

*max overall height

MEASUREMENTS

DIMENSION : 5" W x 7" H
MAX OAH : 128" OAH
HANGING WEIGHT : 2.2 lb

LAMPING

INPUT VOLTAGE : 120V
LUMENS : 500 Rated
BULB : 1 x 40W Xenon G9 , 40W Total
BULB INCLUDED : (Included)
DIMMABLE : Yes
COLOR_TEMP : 2900K

FINISHES OPTION

 Polished Chrome

GLASS

Crystal 20

MATERIAL

Steel, Crystal

RATINGS

cETLus
Dry Location



ADDITIONAL

RATED LIFE 2000 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



Contemporary
Lighting™

WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | et2online.com