

PRODUCT DESCRIPTION

A rippled horizontal bar in Polished Chrome illuminates hand-crafted artisanal Piastra-style glass. The glass's intricate texture creates an interesting light effect on the wall. Can be mounted either vertically as a wall sconce or horizontally over a mirror.

FINISHES OPTION



GLASS

Ripple 124

MATERIAL

Aluminum, Steel, Glass

RATINGS

cETLus
Damp Location
ADA



ADDITIONAL


INSTALL UP/DOWN: Up/Down
RATED LIFE 25000 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

MEASUREMENTS

DIMENSION : 4.75" L x 3.5" W x 24" H x 3.5" Ext
BACK PLATE : 6.75" W x 1.25" H x 12" HCO
HANGING WEIGHT : 7.28 lb

LAMPING

INPUT VOLTAGE : 120V
LUMENS : 1,420 Rated (1,110 Del.)
BULB : 1 x 20W LED AC Integrated , 20W Total
BULB INCLUDED : (Integrated)
DIMMABLE : ELV or Triac CL
CRI : 90 CRI
COLOR_TEMP : 3000K
LIGHTING_DIRECTION : Indirect

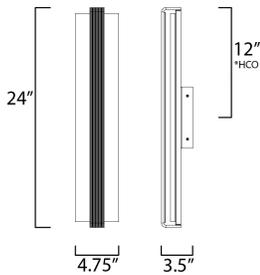

*height from center of outlet to the top of the fixture

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | et2online.com