




**PRODUCT DESCRIPTION**

Rings of Beveled Crystals are mounted into a Polished Chrome band and suspended from cable as if they were floating in air. Multiple size rings mounted in descending order create a unique and brilliant light form which is sure to be the focal point of the room.

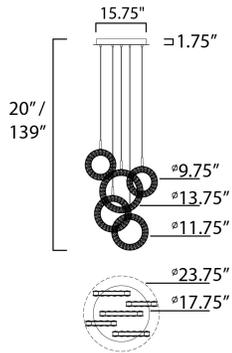

**MEASUREMENTS**

DIMENSION : 23.75" L x 23.75" W x 16.5" H  
 MAX OAH : 138.5" OAH  
 CANOPY : 15.75" W x 15.75" H x 1.75" L  
 HANGING WEIGHT : 28.86 lb

**LAMPING**

INPUT VOLTAGE : 120V  
 LUMENS : 9,130 Rated (5,280 Del.)  
 BULB : 5 x 80W LED PCB Integrated , 83W Total  
 BULB INCLUDED : (Integrated)  
 DIMMABLE : Triac CL or ELV  
 CRI : 90+ CRI  
 COLOR\_TEMP : 3000K

**FINISHES OPTION**

 Polished Chrome

**GLASS**

Crystal 20

**MATERIAL**

Steel, Crystal, Stainless Steel

**RATINGS**

cETLus  
 Dry Location



**ADDITIONAL**

ADJUSTABLE  
 SLOPE: 70  
 RATED LIFE 25000 Hours  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



**WESTERN DISTRIBUTION CENTER (HEADQUARTER)**  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746  
**EASTERN DISTRIBUTION CENTER**  
 4200 SHIRLEY DR. | ATLANTA, GA 30336  
 P. 626.956.4200 | F. 626.956.4225 | et2online.com