




PRODUCT DESCRIPTION

Rings of Beveled Crystals are mounted into a Polished Chrome band and suspended from cable as if they were floating in air. Multiple size rings mounted in descending order create a unique and brilliant light form which is sure to be the focal point of the room.

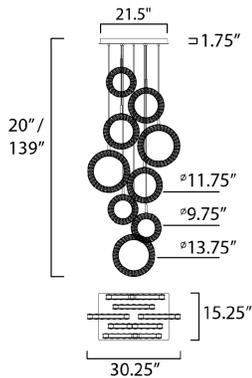

MEASUREMENTS

DIMENSION : 30.25" L x 15.25" W x 16.5" H
 MAX OAH : 138.5" OAH
 CANOPY : 21.75" W x 14.25" H x 1.75" L
 HANGING WEIGHT : 53.37 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 17,600 Rated (7,800 Del.)
 BULB : 9 x 150W LED PCB Integrated , 160W Total
 BULB INCLUDED : (Integrated)
 DIMMABLE : Triac CL or ELV
 CRI : 90+ CRI
 COLOR_TEMP : 3000K

FINISHES OPTION



GLASS

Crystal 20

MATERIAL

Steel, Crystal, Stainless Steel

RATINGS

cETLus
 Dry Location



ADDITIONAL

ADJUSTABLE
 SLOPE: 70
 RATED LIFE 25000 Hours
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
 4200 SHIRLEY DR. | ATLANTA, GA 30336
 P. 626.956.4200 | F. 626.956.4225 | et2online.com