


| Item No. | Pcs. | H    |      |      |     |    |     |   | Inner | W×H×D       | g     |
|----------|------|------|------|------|-----|----|-----|---|-------|-------------|-------|
| 001-S12  | 12   | 0.71 | 0.89 | 1.27 | 1.5 | 2  | 2.5 | 3 | 10    | 220×192×114 | 2,838 |
|          |      | 4    | 5    | 6    | 8   | 10 |     |   |       |             |       |

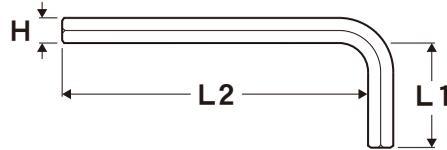

| Item No.   | H             | L1 | L2  |
|------------|---------------|----|-----|
| 001-0.71mm | 0.71 (0.028") | 8  | 34  |
| 001-0.89mm | 0.89 (0.035") | 10 | 34  |
| 001-1.27mm | 1.27 (0.05")  | 14 | 46  |
| 001-1.5mm  | 1.5           | 12 | 52  |
| 001-2mm    | 2             | 12 | 58  |
| 001-2.5mm  | 2.5           | 15 | 60  |
| 001-3mm    | 3             | 20 | 65  |
| 001-4mm    | 4             | 25 | 72  |
| 001-5mm    | 5             | 28 | 80  |
| 001-6mm    | 6             | 32 | 90  |
| 001-8mm    | 8             | 36 | 100 |
| 001-10mm   | 10            | 40 | 112 |

Tool Type: Straight Type  
 Handle Type: L-Key  
 Measurement Type: Metric  
 Additional Information: L-Key Standard Length  
 Surface Treatment: Black Parkalized