


Item No.	Pcs.	H	Inner	W×H×D	g
008-S9Z	9	1/16 5/64 3/32 1/8 5/32 3/16 1/4 5/16 3/8	5	285×120×65	1,967

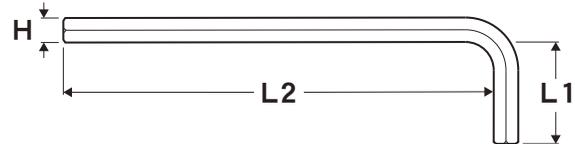

Item No.	H	L1	L2
008-1/16"	1/16"	15	79
008-5/64"	5/64"	17	84
008-3/32"	3/32"	17	92
008-1/8"	1/8"	20	102
008-5/32"	5/32"	25	108
008-3/16"	3/16"	28	118
008-1/4"	1/4"	32	135
008-5/16"	5/16"	36	152
008-3/8"	3/8"	40	170

Tool Type: Straight Type
 Handle Type: L-Key
 Measurement Type: Inch
 Additional Information: L-Key Long Length
 Surface Treatment: Black Parkalized