


Item No.	Pcs.	H	Inner	W×H×D	g
008-S9	9	1.5 2 2.5 3 4 5 6 8 10	5	285×120×65	1,967

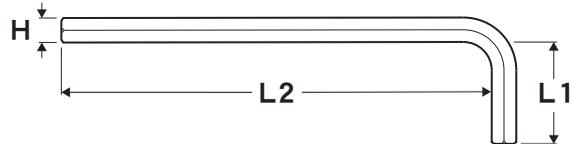

Item No.	H	L1	L2
008-1.5mm	1.5	16	79
008-2mm	2	17	86
008-2.5mm	2.5	18	94
008-3mm	3	20	101
008-4mm	4	25	110
008-5mm	5	28	120
008-6mm	6	32	133
008-8mm	8	36	154
008-10mm	10	40	172

Tool Type: Straight Type
 Handle Type: L-Key
 Measurement Type: Metric
 Additional Information: L-Key Long Length
 Surface Treatment: Black Parkalized