


Item No.	Pcs.	H					Inner	W×H×D	g				
014-S9Z	9	1/16	5/64	3/32	1/8	5/32	3/16	1/4	5/16	3/8	5	311×120×61	2,260

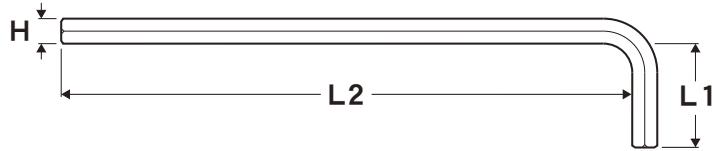

Item No.	H	L1	L2	Inner	W×H×D	g
014-1/16"	1/16"	15	79	20	162×68×35	61
014-5/64"	5/64"	17	93	20	162×68×35	81
014-3/32"	3/32"	18	108	20	162×68×35	121
014-1/8"	1/8"	20	127	20	162×68×35	221
014-5/32"	5/32"	25	140	20	162×68×35	361
014-3/16"	3/16"	28	158	20	202×65×32	524
014-1/4"	1/4"	32	178	20	226×75×32	1,184
014-5/16"	5/16"	36	198	10	226×75×32	1,031
014-3/8"	3/8"	40	222	10	250×90×38	1,661

Tool Type: Straight Type  
 Handle Type: L-Key  
 Measurement Type: Inch  
 Additional Information: L-Key Extra Long Length  
 Surface Treatment: Black Parkalized