


Item No.	Pcs.	H	Inner	W×H×D	g
016-13ZD	13	0.05" 1/16 5/64 3/32 7/64 1/8 9/64 5/32 3/16 7/32 1/4 5/16 3/8	5	210×144×85	2,418

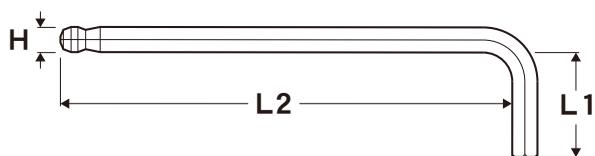

Item No.	H	L1	L2
016-0.05"	0.05"(1.27mm)	14	75
016-1/16"	1/16"	15	79
016-5/64"	5/64"	17	84
016-3/32"	3/32"	17	92
016-7/64"	7/64"	19	97
016-1/8"	1/8"	20	102
016-9/64"	9/64"	23	104
016-5/32"	5/32"	25	108
016-3/16"	3/16"	28	118
016-7/32"	7/32"	30	125
016-1/4"	1/4"	32	135
016-5/16"	5/16"	36	152
016-3/8"	3/8"	40	170

Tool Type: Ball Point  
 Handle Type: L-Key  
 Measurement Type: Inch  
 Additional Information: L-Key Long Length  
 Surface Treatment: Black Parkalized