


Item No.	Pcs.	H					Inner	W×H×D	g				
016-1510D	9	1.5	2	2.5	3	4	5	6	8	10	5	257×103×126	2,097

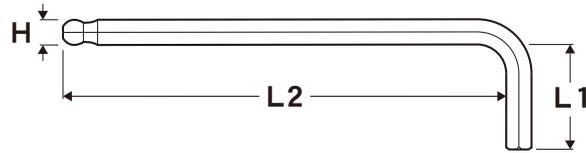

Item No.	H	L1	L2
016-1.5mm	1.5	16	79
016-2mm	2	17	86
016-2.5mm	2.5	18	94
016-3mm	3	20	101
016-4mm	4	25	110
016-5mm	5	28	120
016-6mm	6	32	133
016-8mm	8	36	154
016-10mm	10	40	172

Tool Type: Ball Point
 Handle Type: L-Key
 Measurement Type: Metric
 Additional Information: L-Key Long Length
 Surface Treatment: Black Parkalized