


Item No.	Pcs.	H						Inner	W×H×D	g
BDS-6	6	1.5	2	2.5	3	4	5	5	244×160×84	1,349

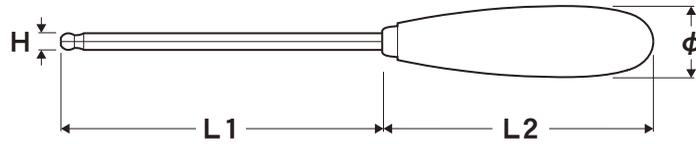

Item No.	H	L1	L2	Φ
BD-1.5	1.5	65	69	18
BD-2	2	70	69	18
BD-2.5	2.5	75	84	22
BD-3	3	80	84	22
BD-4	4	90	99	26
BD-5	5	100	99	26

Tool Type: Ball Point  
 Handle Type: SCREWDRIVER  
 Measurement Type: Metric  
 Additional Information: Plastic Handle