


Item No.	Pcs.	T	Inner	W×H×D	g
EA-310C-5S10	5	T10 T15 T20 T25 T30	10	305×100×110	2,436

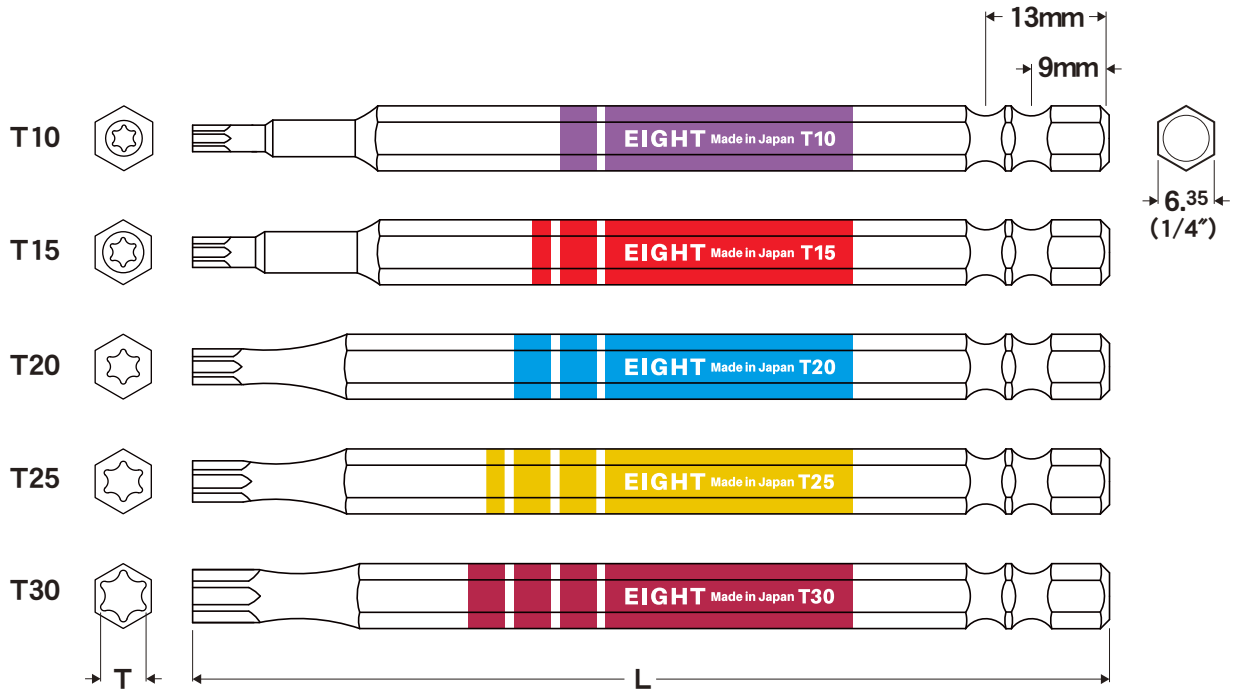

Item No.	T	L
EA-310C T10×10	T10	100
EA-310C T15×10	T15	100
EA-310C T20×10	T20	100
EA-310C T25×10	T25	100
EA-310C T30×10	T30	100

- Tool Type: Torx®
- Measurement Type: Torx®
- Additional Information: 6.35 mm SHANK
- Additional Information: 9 mm & 13mm groove
- Additional Information: Torsion processing
- Additional Information: Color printed