


Item No.	Pcs.	T	Inner	W×H×D	g
EA-310-5S10	5	T10 T15 T20 T25 T30	10	305×100×110	2,436

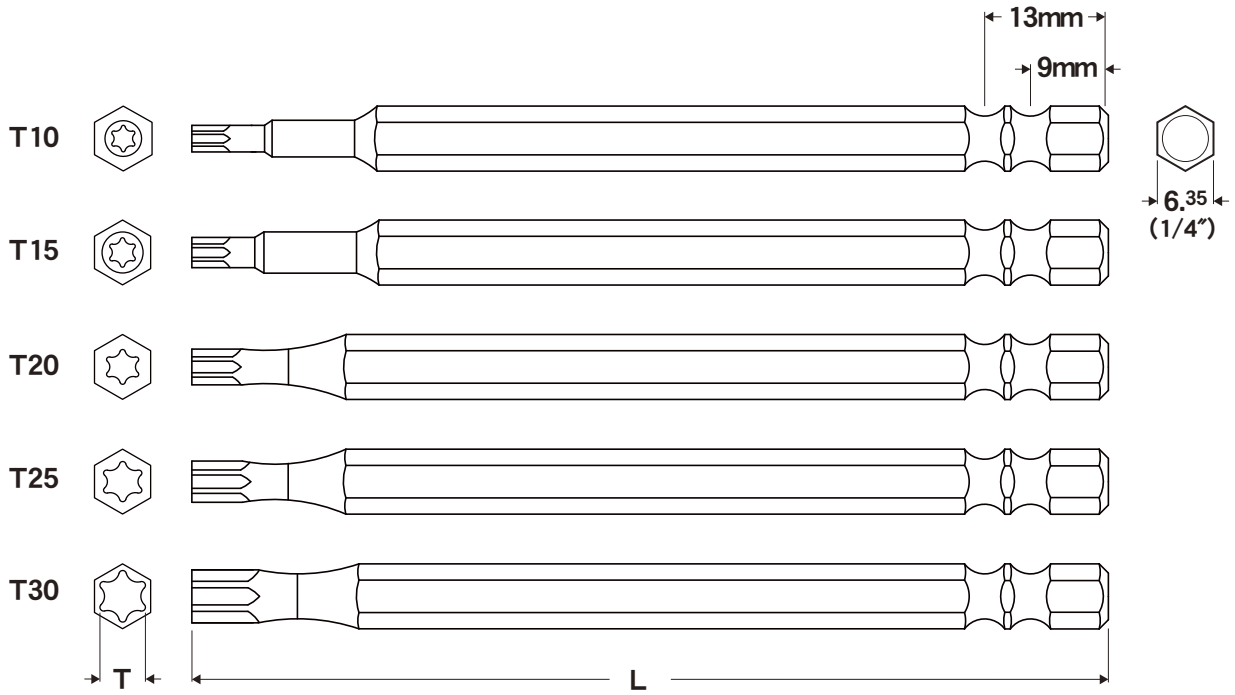

Item No.	T	L
EA-310 T10×100	T10	100
EA-310 T15×100	T15	100
EA-310 T20×100	T20	100
EA-310 T25×100	T25	100
EA-310 T30×100	T30	100

Tool Type: Torx®

Measurement Type: Torx®

Additional Information: 6.35 mm SHANK

Additional Information: 9 mm & 13mm groove

Additional Information: Torsion processing