


| Item No. | Pcs. | H | Inner | W×H×D | g |
|--------------|------|-------------|-------|-------------|-------|
| EA-610C-5S10 | 5 | 2.5 3 4 5 6 | 10 | 305×100×110 | 2,436 |

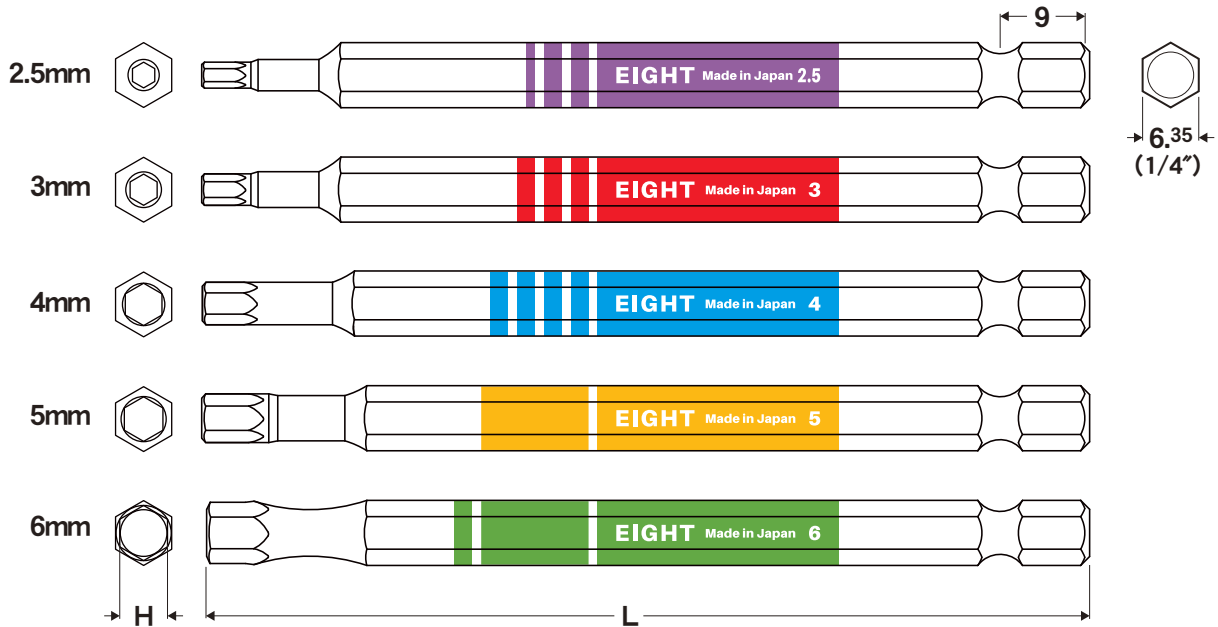

| Item No. | H | L |
|-------------------|-----|-----|
| EA-610C 2.5mm×100 | 2.5 | 100 |
| EA-610C 3mm×100 | 3 | 100 |
| EA-610C 4mm×100 | 4 | 100 |
| EA-610C 5mm×100 | 5 | 100 |
| EA-610C 6mm×100 | 6 | 100 |

Tool Type: Straight Type
 Measurement Type: Metric
 Additional Information: 6.35 mm SHANK
 Additional Information: 9 mm groove
 Additional Information: Torsion processing
 Additional Information: Color printed