


Item No.	Pcs.	H	Inner	W×H×D	g
EA-610C-5S65	5	2.5 3 4 5 6	10	305×100×110	2,436

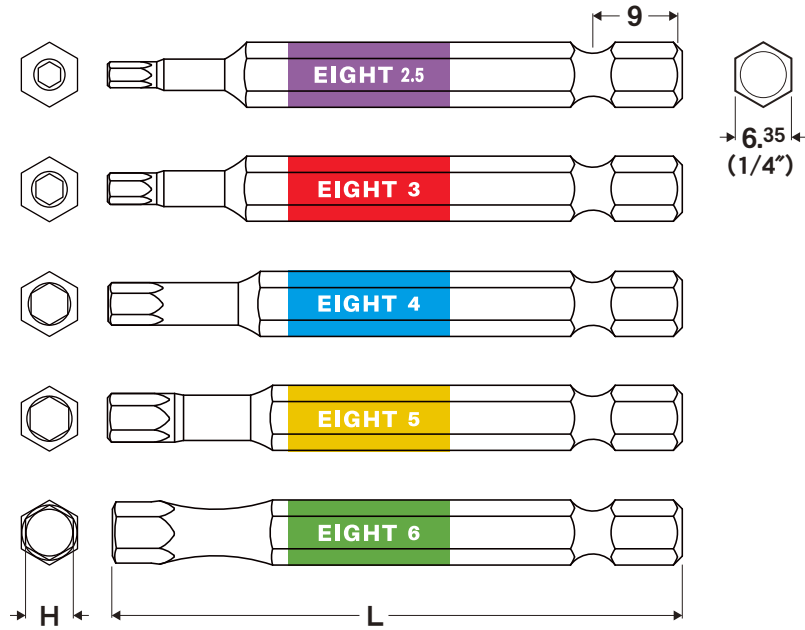

Item No.	H	L
EA-610C 2.5mm×65	2.5	65
EA-610C 3mm×65	3	65
EA-610C 4mm×65	4	65
EA-610C 5mm×65	5	65
EA-610C 6mm×65	6	65

Tool Type: Straight Type

Measurement Type: Metric

Additional Information: 6.35 mm SHANK

Additional Information: 9 mm groove

Additional Information: Torsion processing

Additional Information: Color printed