


Item No.	Pcs.	H	Inner	W×H×D	g
EA-610-5S10	5	2.5 3 4 5 6	10	305×100×110	2,436

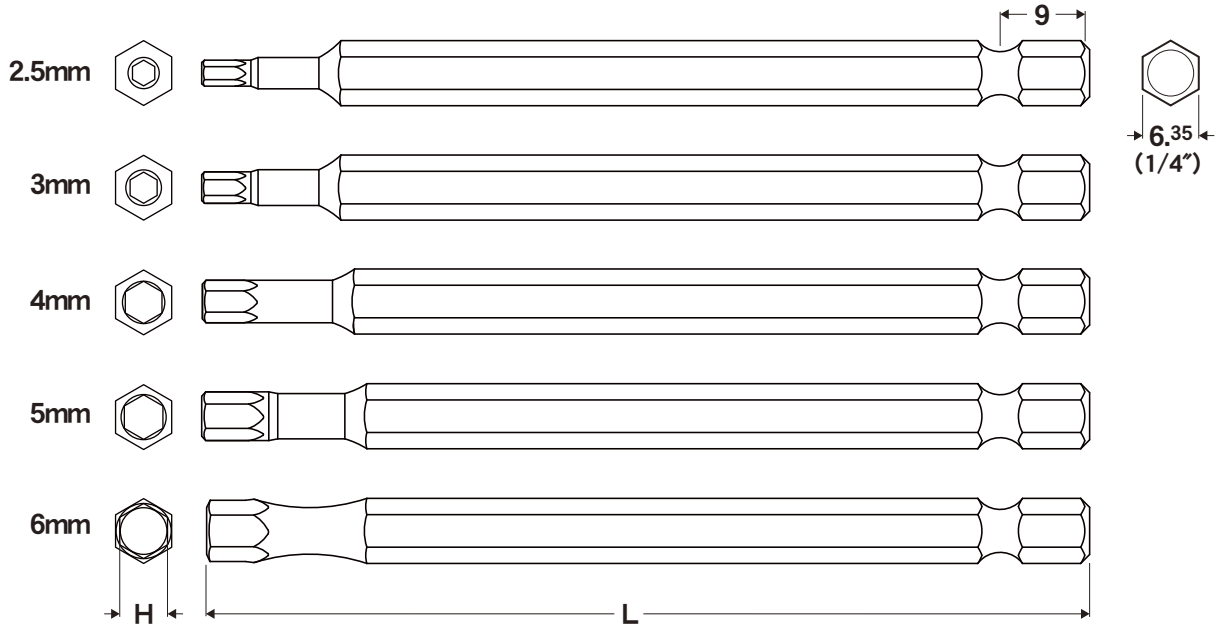

Item No.	H	L
EA-610 2.5mm×100	2.5	100
EA-610 3mm×100	3	100
EA-610 4mm×100	4	100
EA-610 5mm×100	5	100
EA-610 6mm×100	6	100

Tool Type: Straight Type  
 Measurement Type: Metric  
 Additional Information: 6.35 mm SHANK  
 Additional Information: 9 mm groove  
 Additional Information: Torsion processing