


Item No.	Pcs.	H	Inner	W×H×D	g
LHS-7	7	1.5 2 2.5 3 4 5 6	10	256×160×53	1,535

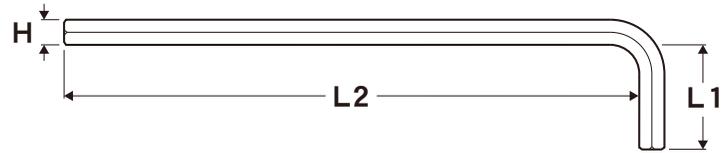

Item No.	H	L1	L2
LH-1.5	1.5	16	79
LH-2	2	17	95
LH-2.5	2.5	18	110
LH-3	3	20	126
LH-4	4	25	142
LH-5	5	28	160
LH-6	6	32	180

Tool Type: Straight Type
 Handle Type: L-Key
 Measurement Type: Metric
 Additional Information: L-Key Extra Long Length