


| Item No. | Pcs. | H | Inner | W×H×D | g |
|----------|------|---|-------|-------------|-------|
| LHS-9ZD | 9 | 1/16 5/64 3/32 1/8 5/32 3/16 1/4 5/16 3/8 | 5 | 320×103×114 | 2,478 |

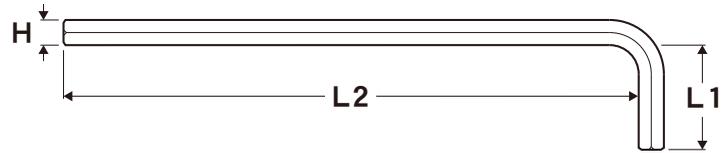

| Item No. | H | L1 | L2 |
|----------|------|----|-----|
| LH-1/16 | 1/16 | 15 | 79 |
| LH-5/64 | 5/64 | 17 | 93 |
| LH-3/32 | 3/32 | 18 | 108 |
| LH-1/8 | 1/8 | 20 | 127 |
| LH-5/32 | 5/32 | 25 | 140 |
| LH-3/16 | 3/16 | 28 | 158 |
| LH-1/4 | 1/4 | 32 | 178 |
| LH-5/16 | 5/16 | 36 | 198 |
| LH-3/8 | 3/8 | 40 | 222 |

Tool Type: Straight Type
 Handle Type: L-Key
 Measurement Type: Inch
 Additional Information: L-Key Extra Long Length