



Item No.	Pcs.	H								Inner	W×H×D	g	
LHS-9ZNP	9	1/16	5/64	3/32	1/8	5/32	3/16	1/4	5/16	3/8	5	305×103×125	3,159

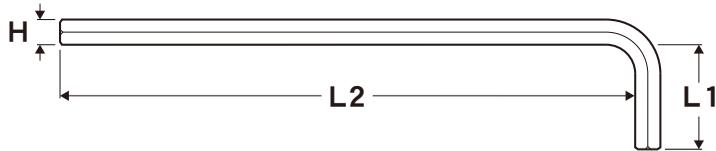

Item No.	H	L1	L2
LH-1/16	1/16	15	79
LH-5/64	5/64	17	93
LH-3/32	3/32	18	108
LH-1/8	1/8	20	127
LH-5/32	5/32	25	140
LH-3/16	3/16	28	158
LH-1/4	1/4	32	178
LH-5/16	5/16	36	198
LH-3/8	3/8	40	222

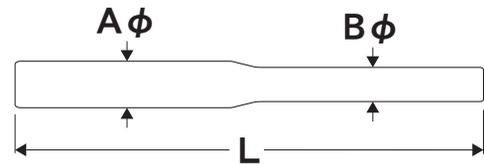

L	Aφ	Bφ
150	15.9	14.2
110	9.5	8.5

Tool Type:

Straight Type

Handle Type:

L-Key

Measurement Type:

Inch

Additional Information:

L-Key Extra Long Length

Additional Information:

Extension Pipes x 2 pcs.