


Item No.	Pcs.	H							Inner	W×H×D	g
M-7MH	7	0.71	0.89	1.27	1.5	2	2.5	3	20	192×129×54	612

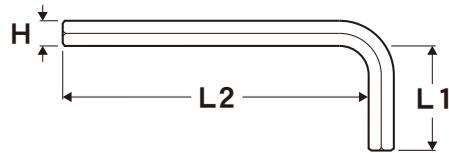

Item No.	H	L1	L2
001-0.71mm	0.71 (0.028")	8	34
001-0.89mm	0.89 (0.035")	10	34
001-1.27mm	1.27 (0.05")	14	46
001-1.5mm	1.5	12	52
001-2mm	2	12	58
001-2.5mm	2.5	15	60
001-3mm	3	20	65

Tool Type: Straight Type
 Handle Type: L-Key
 Measurement Type: Metric
 Additional Information: L-Key Standard Length
 Surface Treatment: Black Parkalized