


Item No.	Pcs.	H	Inner	W×H×D	g
RS-8	8	1.5 2 2.5 3 4 5 6 8	5	187×102×59	820

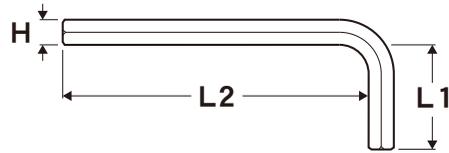

Item No.	H	L1	L2
R-1.5	1.5	12	52
R-2	2	12	58
R-2.5	2.5	15	60
R-3	3	20	65
R-4	4	25	72
R-5	5	28	80
R-6	6	32	90
R-8	8	36	100

Tool Type: Straight Type
 Handle Type: L-Key
 Measurement Type: Metric
 Additional Information: L-Key Standard Length