


Item No.	Pcs.	H	Inner	W×H×D	g
TEL-S9NPGR	9	1/16 5/64 3/32 1/8 5/32 3/16 1/4 5/16 3/8	5	305×100×110	2,436

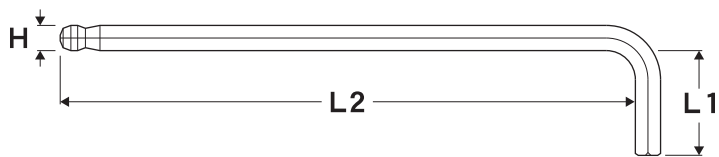

Item No.	H	L1	L2
TEL-1/16GR	1/16	15	79
TEL-5/64GR	5/64	17	93
TEL-3/32GR	3/32	18	108
TEL-1/8GR	1/8	20	127
TEL-5/32GR	5/32	25	140
TEL-3/16GR	3/16	28	158
TEL-1/4GR	1/4	32	178
TEL-5/16GR	5/16	36	198
TEL-3/8GR	3/8	40	222



L	Aφ	Bφ
150	15.9	14.2
110	9.5	8.5

Tool Type:

Taper Head

Handle Type:

L-Key

Measurement Type:

Inch

Additional Information:

L-Key Extra Long Length

Additional Information:

Single-Color GREEN

Additional Information:

Extension Pipes x 2 pcs.