


Item No.	Pcs.	H	Inner	W×H×D	g
TEL-S9NPPU	9	1/16 5/64 3/32 1/8 5/32 3/16 1/4 5/16 3/8	5	305×100×110	2,436

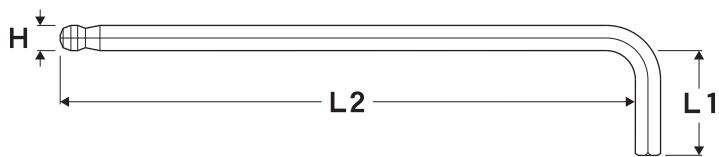

Item No.	H	L1	L2
TEL-1/16PU	1/16	15	79
TEL-5/64PU	5/64	17	93
TEL-3/32PU	3/32	18	108
TEL-1/8PU	1/8	20	127
TEL-5/32PU	5/32	25	140
TEL-3/16PU	3/16	28	158
TEL-1/4PU	1/4	32	178
TEL-5/16PU	5/16	36	198
TEL-3/8PU	3/8	40	222



L	Aφ	Bφ
150	15.9	14.2
110	9.5	8.5

Tool Type:

Taper Head

Handle Type:

L-Key

Measurement Type:

Inch

Additional Information:

L-Key Extra Long Length

Additional Information:

Single-Color PURPLE

Additional Information:

Extension Pipes x 2 pcs.