


| Item No.   | Pcs. | H   | Inner | W×H×D       | g     |
|------------|------|---|-------|-------------|-------|
| TELC-S9NRE | 9    | 1/16 5/64 3/32 1/8 5/32 3/16 1/4 5/16 3/8 | 5     | 305×100×110 | 2,436 |

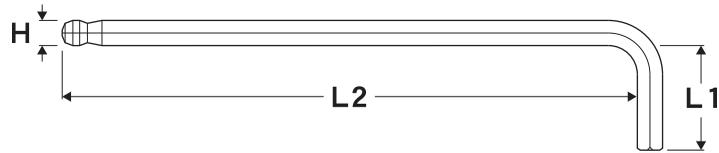

| Item No.   | H    | L1 | L2  |
|------------|------|----|-----|
| TEL-1/16RE | 1/16 | 15 | 79  |
| TEL-5/64RE | 5/64 | 17 | 93  |
| TEL-3/32RE | 3/32 | 18 | 108 |
| TEL-1/8RE  | 1/8  | 20 | 127 |
| TEL-5/32RE | 5/32 | 25 | 140 |
| TEL-3/16RE | 3/16 | 28 | 158 |
| TEL-1/4RE  | 1/4  | 32 | 178 |
| TEL-5/16RE | 5/16 | 36 | 198 |
| TEL-3/8RE  | 3/8  | 40 | 222 |

Tool Type: Taper Head  
 Handle Type: L-Key  
 Measurement Type: Inch  
 Additional Information: L-Key Extra Long Length  
 Additional Information: Single-Color RED