







Item No.	Pcs.	H								Inner	W×H×D	g	
TLC-S9N	9	1.5	2	2.5	3	4	5	6	8	10	5	305×100×110	2,436

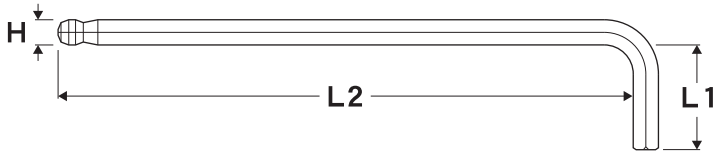

Item No.	H	L1	L2	Color
TLC-1.5	1.5	16	79	White 
TLC-2	2	17	95	Gunmetal 
TLC-2.5	2.5	18	110	Mauve 
TLC-3	3	20	126	Red 
TLC-4	4	25	142	light blue 
TLC-5	5	28	160	Bright yellow 
TLC-6	6	32	180	Green 
TLC-8	8	36	200	Rose 
TLC-10	10	40	224	Pink 

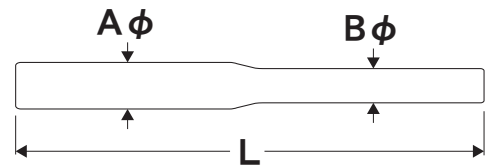

L	Aφ	Bφ
150	15.9	14.2
110	9.5	8.5

Tool Type: Taper Head
 Handle Type: L-Key
 Measurement Type: Metric
 Additional Information: L-Key Extra Long Length
 Additional Information: Multi-Color
 Additional Information: Extension Pipes x 2 pcs.