


Item No.	Pcs.	H										Inner	W×H×D	g
TLS-9NP	9	1.5	2	2.5	3	4	5	6	8	10	5	305×100×110	2,431	

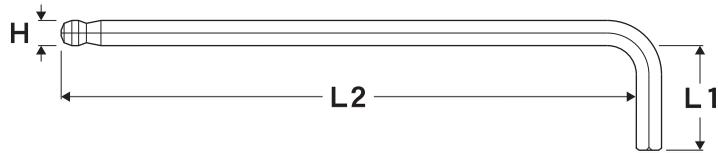

Item No.	H	L1	L2
TL-1.5	1.5	16	79
TL-2	2	17	95
TL-2.5	2.5	18	110
TL-3	3	20	126
TL-4	4	25	142
TL-5	5	28	160
TL-6	6	32	180
TL-8	8	36	200
TL-10	10	40	224



L	Aφ	Bφ
150	15.9	14.2
110	9.5	8.5

Tool Type:

Taper Head

Handle Type:

L-Key

Measurement Type:

Metric

Additional Information:

L-Key Extra Long Length

Additional Information:

Extension Pipes x 2 pcs.