


Item No.	Pcs.	H								Inner	W×H×D	g
TXBH-S8	8	T8	T10	T15	T20	T25	T27	T30	T40	5	217x94x88	975

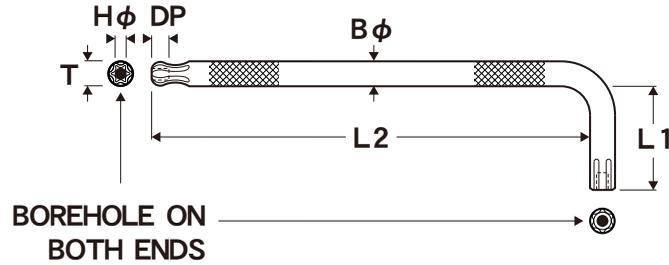

Item No.	T	L1	L2	Bφ	Hφ	DP
TXBH-8	T 8	17	86	2.5	0.7	1.0
TXBH-10	T 10	18	94	2.7	1.0	1.2
TXBH-15	T 15	21	99	3.3	1.3	1.6
TXBH-20	T 20	22	106	3.8	1.8	2.0
TXBH-25	T 25	25	110	4.4	2.1	2.1
TXBH-27	T 27	27	115	5.0	2.4	2.3
TXBH-30	T 30	29	123	5.5	2.7	2.5
TXBH-40	T 40	32	133	6.6	3.2	3.1

Tool Type: Torx® Ball Point

Handle Type: L-Key

Measurement Type: Torx®

Additional Information: L-Key Long Length

Additional Information: Borehole On Both Ends