


Item No.	Pcs.	H										Inner	W×H×D	g
TXEL-S13	13	T5	T6	T7	T8	T9	T10	T15	T20	T25		5	325×105×140	2,255
		T27	T30	T40	T50									

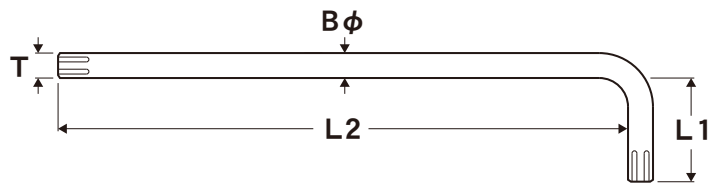

Item No.	T	L1	L2	Bφ
TXEL-5	T 5	16	79	2.3
TXEL-6	T 6	16	85	2.3
TXEL-7	T 7	16	90	2.3
TXEL-8	T 8	16	100	2.3
TXEL-9	T 9	18	113	2.5
TXEL-10	T 10	20	113	2.7
TXEL-15	T 15	21	122	3.2
TXEL-20	T 20	23	133	3.8
TXEL-25	T 25	25	144	4.4
TXEL-27	T 27	30	152	5.0
TXEL-30	T 30	31	160	5.5
TXEL-40	T 40	35	180	6.6
TXEL-50	T 50	40	200	8.8

Tool Type:	Torx®
Handle Type:	L-Key
Measurement Type:	Torx®
Additional Information:	L-Key Extra Long Length